

Self locking counter nut

DIN Sta

PAL



For axial locking

- Self locking nut
- Conforms to DIN 7967
- Stainless steel A2

Advantages

- Self locking on threaded shafts

stainless
steel

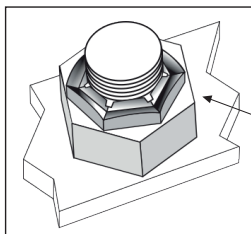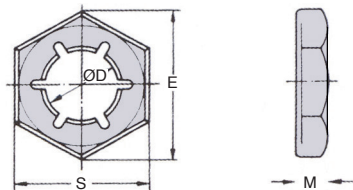

Used as a
counter nut

Typical application

DISCOUNTS

Qty	1+	6+	11+
Disc.	List	-10%	On request

Part number	For thread				Quantity per box	Stock*	Price each 1 to 5
	ØD	M	E	S			
PAL-M5/B	M5	5	8,79	8	500	✓	18,48 €
PAL-M6/B	M6	6	11,05	10	200	✓	8,77 €
PAL-M8/B	M8	8	14,38	13	100	✓	11,73 €
PAL-M10/B	M10	10	16,64	15	100	✓	6,59 €
PAL-M12/B	M12	12	20,03	18	100	-	8,43 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



RURp

Swivel castor with double brake, Polyurethane - Aluminium rim (Free



RHTtcss

High Temperature Castor, up to 200kg



CMA

Eye bolt, Steel



MPE

Hexagonal spacer, Steel



PTA150

Articulated levelling foot, pressed base Ø150, Ø 150



ECF

Well nut, Chloroprene elastomer



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120 with counter and han...



STRIP

Sealing brush strip, 3m length



 
FHCSS

Countersunk screw, Stainless steel A2 -



BPHF

Ball transfer unit push fit, Heavy



PTA80

 
Articulated levelling foot, pressed base



RJA10_03


Sealing strip, Clipsing

Complementary products



CXS

 External circlip DIN471, external DIN 471



CYS

Internal circlip DIN472, internal DIN 472



BFA

Shaft locking washer, E clip