

# Self locking counter nut

DIN Sta

## PAL



## For axial locking

- Self locking nut
- Conforms to DIN 7967
- Stainless steel A2

### Advantages

- Self locking on threaded shafts

stainless steel

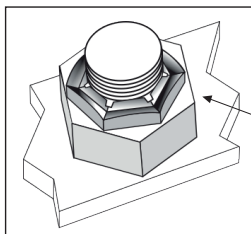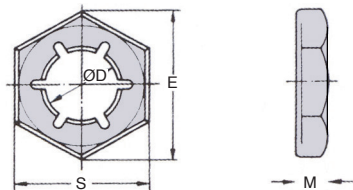

Used as a counter nut

Typical application

### DISCOUNTS

Qty	1+	6+	11+
Disc.	List	-10%	On request

Part number	For thread				Quantity per box	Stock*	Price each 1 to 5
	ØD	M	E	S			
PAL-M5/B	M5	5	8,79	8	500	✓	18,48 €
PAL-M6/B	M6	6	11,05	10	200	✓	8,77 €
PAL-M8/B	M8	8	14,38	13	100	✓	11,73 €
PAL-M10/B	M10	10	16,64	15	100	✓	6,59 €
PAL-M12/B	M12	12	20,03	18	100	-	8,43 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

 
## Our other products




PRF\_FIX\_ANG  
Fastener for aluminium profile, Angular joint



CDR  
Retaining cable for ball pin, Retaining cable



LRH  
Bi-directional leadscrew, Bi-directional - 1 thread

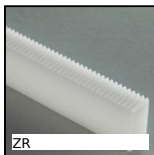

ZR  
Plastic rack, Delrin



BH02  
Single housed bearing assembly, Bearing secured with circlips



PX  
Optimal output shaft stainless steel, P gearboxes double sided outp...



HBM  
Adjustment bushing for half-rail guide, Adjustment bushing



FBL4004\_K7  
Brush strip per meter PA6 fibres Ø0.3 to Ø0.5, Black polyamide 6 -...



RBS  
Dynamic washer DIN2093, Steel



WW10  
Drylin® W slide, slide assembly




CMA  
Eye bolt, Steel




BOXsap  
Boxed set of spring pins ISO8752, Boxed set - Split ISO 8752

## Complementary products

 

 CXS  
External circlip DIN471, external DIN 471



CYS  
Internal circlip DIN472, internal DIN 472



BFA  
Shaft locking washer, E clip