

# Stainless steel articulated foot Stock Size XS

PAMss

Maximum load 9,000N


- Tilting foot
- Tilt: +/- 5° from vertical
- Materials:  
Base and spindle: stainless steel 1.4301 (304)  
Sole: vulcanised rubber (Shore hardness 90)
- Ø30 and Ø40mm bases available

## Uses

- Laboratory furniture
- Medical and food industries

## Note

- Values for static load given at 50% of spindle length. With dynamic or vibrating loads, value will be lower

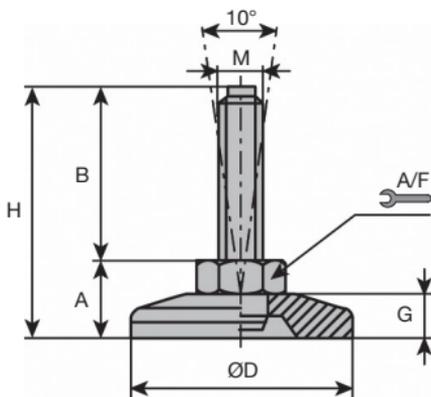

Small sizes



solid stainless steel

## DISCOUNTS

Qty	1+	12+	20+	40+
Disc.	List	-5%	-10%	On request

Part number	A	B	ØD	A/F	M	G	H	Static load (N)	Stock*	Price each 1 to 11
PAM30-8-25/SS	14	25	30	14	M8	8	39	8000	✓	19,29 €
PAM30-8-50/SS	14	50	30	14	M8	8	64	8000	✓	20,19 €
PAM30-10-25/SS	14	25	30	14	M10	8	39	8000	-	19,29 €
PAM30-10-50/SS	14	50	30	14	M10	8	64	8000	✓	20,19 €
PAM30-10-75/SS	14	75	30	14	M10	8	89	8000	✓	23,91 €
PAM38-8-25/SS	14	25	40	14	M8	8	39	9000	✓	21,69 €
PAM38-8-50/SS	14	50	40	14	M8	8	64	9000	✓	23,81 €
PAM38-10-25/SS	14	25	40	14	M10	8	39	9000	-	21,69 €
PAM38-10-50/SS	14	50	40	14	M10	8	64	9000	-	23,81 €
PAM38-10-75/SS	14	75	40	14	M10	8	89	9000	✓	25,42 €
PAM38-12-50/SS	14	50	40	14	M12	8	64	9000	✓	23,81 €
PAM38-12-100/SS	14	100	40	14	M12	8	114	9000	✓	27,22 €

\*Depending on availability - Dimensions in mm