

- **Tilting foot**
- **Tilt: +/- 5° from vertical**
- **Materials:**
 - Base and spindle: stainless steel 1.4301 (304)
 - Sole: vulcanised rubber (Shore hardness 90)
- Ø30 and Ø40mm bases available

Uses

- Laboratory furniture
- Medical and food industries


Note

- Values for static load given at 50% of spindle length. With dynamic or vibrating loads, value will be lower

Small sizes



solid stainless steel

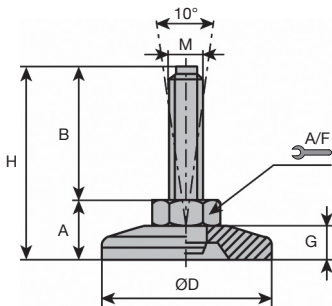

DISCOUNTS

Qty	1+	12+	20+	40+
Disc.	List	-5%	-10%	On request

Part number	A	B	ØD	A/F	M	G	H	Static load (N)	Stock*	Price each 1 to 11
PAM30-8-25/SS	14	25	30	14	M8	8	39	8000	✓	17,85 €
PAM30-8-50/SS	14	50	30	14	M8	8	64	8000	✓	18,68 €
PAM30-10-25/SS	14	25	30	14	M10	8	39	8000	✓	17,85 €
PAM30-10-50/SS	14	50	30	14	M10	8	64	8000	✓	18,68 €
PAM30-10-75/SS	14	75	30	14	M10	8	89	8000	✓	22,12 €
PAM38-8-25/SS	14	25	40	14	M8	8	39	9000	✓	20,07 €
PAM38-8-50/SS	14	50	40	14	M8	8	64	9000	✓	22,03 €
PAM38-10-25/SS	14	25	40	14	M10	8	39	9000	-	20,07 €
PAM38-10-50/SS	14	50	40	14	M10	8	64	9000	✓	22,03 €
PAM38-10-75/SS	14	75	40	14	M10	8	89	9000	✓	23,52 €
PAM38-12-50/SS	14	50	40	14	M12	8	64	9000	✓	22,03 €
PAM38-12-100/SS	14	100	40	14	M12	8	114	9000	✓	25,18 €

 
*Depending on availability - Dimensions in mm

Our other products



T0

Torsion spring,
Stainless steel



RPP

Connecting plate for
RPP type timing belts,
RPPB



TAC

Rigging screw
(hook/eye), Steel



DOMI80

Accessories, Clamping
lever



ACL-APB

Closing system for
aluminium profile,
Magnetic door stop



SMS

Spiral bevel gear, 1:1



LR

Precision locknut,
Precision locknut



BAG

Steel Clamping collar,
Steel



CHINV2

Invisible hinge,
Invisible - Opening up
to 125°



CNA-CNG

Right angled
mounting plate, Right
angled mounting
plate for ball jo...



RHTplss

High Temperature
Castor, up to 200kg



D19 D29

Compression springs
in metre length
stainless steel, by the
metre

Complementary products



PRS30

Stainless steel
articulated foot Ø30,
Ø 30