

Articulated foot with sheet metal base Ø100

PAMF100

Max load: 15,000N
Rubber sole in EPDM, blue



- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special pad for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

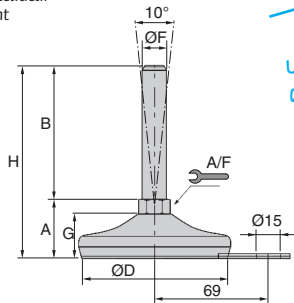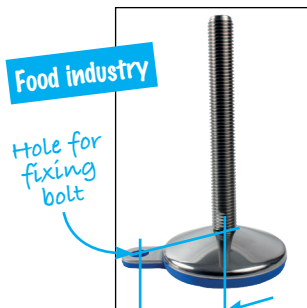

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price	-5%	-10%	-15%	On request	

References	Threading		B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
	ØD	ØF							
PAMF100-16-100/EB	100	M16	100	39.5	13	30	139.5	15000	53,37€
PAMF100-16-150/EB	100	M16	150	39.5	13	30	189.5	15000	54,99€
PAMF100-16-200/EB	100	M16	200	39.5	13	30	239.5	15000	58,69€
PAMF100-20-100/EB	100	M20	100	43.0	17	30	143.0	15000	56,55€
PAMF100-20-150/EB	100	M20	150	43.0	17	30	193.0	15000	59,76€
PAMF100-20-200/EB	100	M20	200	43.0	17	30	243.0	15000	63,46€


* Depending on availability - Dimensions in mm

Our other products




DOMI120

 Accessories,
Turntable



H1

 Crossed helical gear
crossed axis à 90°,
Machined plastic
(delrin)



T2

T-type timing belt,
T2.5 Steel cored
polyurethane



SNG

Pillow block, Cast iron
- Split pillow



EMR

Fast-locking knurled
nut, Knurled



LVT

Miniature motorised
actuator, 4A, 4
ampers



PSG2

Spur gear - precision
range, Case hardened
steel 20NCD2



BS3

Panamech, Multi-
Beam stainless steel,
Stainless steel - with
set screw



GDR880

Straight track for
plate chain, Ranges
880 and 881



LRX

Linear roller slide, Rail
- from 9410 N to
101000 N



SSE

Stainless steel
spherical bearing,
Stainless steel / PTFE



T5M T10M

T-type timing belt per
metre, T5 Steel cored
polyurethane

Complementary products



PTA50ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA80ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA100ssEB

Articulated foot with
sheet metal base,
Articulated foot



PAMF80EB

Articulated foot with
sheet metal base,
Articulated foot