



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PAMF80


- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

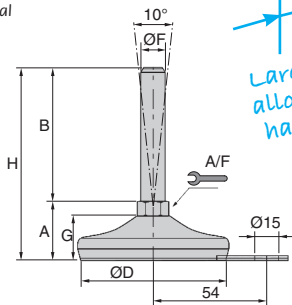

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/SS/EB	80	M12	100	35	14	25	135	10000	29,62€
PAMF80-12-150/SS/EB	80	M12	150	35	14	25	185	10000	31,76€
PAMF80-16-100/SS/EB	80	M16	100	35	13	25	135	10000	31,76€
PAMF80-16-150/SS/EB	80	M16	150	35	13	25	185	10000	33,84€
PAMF80-20-100/SS/EB	80	M20	100	38	17	25	138	10000	35,47€
PAMF80-20-150/SS/EB	80	M20	150	38	17	25	188	10000	38,07€
PAMF80-20-200/SS/EB	80	M20	200	38	17	25	238	10000	42,04€

*Within the limits of available stock - Dimensions in mm

Our other products



T10-BAR
Toothed bar stock,
T10



P55
Worm and wheel
gearbox, up to 57 Nm



GCA
Spring pin, Linch



PPS05
Pinion shaft -
precision range, Pre-
hardened steel
35NCD6



IN0
Internal gear, Steel
20NCD2



CHM40
Worm and wheel
gearbox, up to 57 Nm



RPPM
RPP type belt by the
metre, RPP5 Steel
cored polyurethane



LVT
Miniature motorised
actuator, 2 amperes



AT5_16
Synchronous pulley,
AT5 aluminium



F7-P-AM
Multifunction display,
Magnetic band



DOG319
DC Motor and gearbox
combination, from 4
to 9 Nm



BOXKK
Key, Boxed set - Steel
or stainless steel

Complementary products



PARF80
Rigid foot, Swivelling -
Ø80