



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PAMF80

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

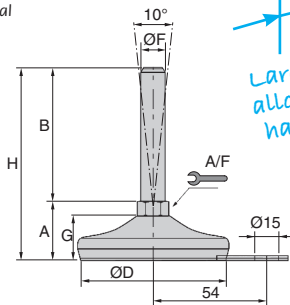

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price		-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	36,75 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	38,83 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	37,24 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	39,90 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	42,53 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	42,53 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	45,16 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	49,11 €

*Within the limits of available stock - Dimensions in mm

Our other products



NCT
Square tube
connector, Fixed
angle



RPCpl
Swivel castor with
plate, Steel -
Polyamide



TAC_SS
Stainless steel rigging
screw (hook/eye),
Stainless steel



PLM-SC
Magnetic stud with
central countersunk
hole, With milled bore



HTD8M-BAR
HTD type tooth bar
stock, HTD8



CHA1056-U4
Screwed hinge, 180°



CABPVC
PVC covered
galvanised steel
cable, Galvanised
steel with



BLHB60
Right angled gearbox,
bored shafts, up to 70
Nm



KH
Linear bearing, Light



PRF_BM
Base support plate for
aluminium profile,
Central base fixation



VELprf
Clip-on base for hook-
and-loop strip,
Polyamide



PF60
Worm and wheel gear
reducer, up to 118
Nm

Complementary products



PTA50ssEB
Articulated foot with
sheet metal base
Ø50, Articulated foot



PTA80ssEB
Articulated foot with
sheet metal base
Ø80, Articulated foot



PTA100ssEB
Articulated foot with
sheet metal base
Ø100, Articulated foot



PAMF100EB
Articulated foot with
sheet metal base
Ø100, Articulated foot