



# Articulated foot with sheet metal base Ø80

Max load: 10,000N  
Rubber sole in EPDM, blue

PAMF80

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

## Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

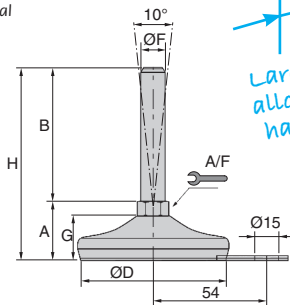

## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price		-5%	-10%	-15%	On request

 
Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	36,75 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	38,83 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	37,24 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	39,90 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	42,53 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	42,53 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	45,16 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	49,11 €

\*Within the limits of available stock - Dimensions in mm

## Our other products



PDR-RD  
Mounting feet with  
integrated castors,  
Offset castor



T2  
T type timing belt,  
T2.5 Steel cored  
polyurethane



CHC  
Socket headed screw,  
Steel class 12.19



LRM2  
Cylindrical bronze nut,  
Bronze - 2 threads



PRESSHR  
Manual workbench  
press, Force up to  
500kg



WINGbrEcrou  
Manually tightened  
wing nut DIN315,  
Brass DIN 315



CHB  
Worm and wheel gear  
reducer, up to 73 Nm



SNG  
Stainless/Polymer  
pillow block bearing,  
Cast iron - Split pillow



CCL  
Standard wire  
thimble, Steel



EMR  
Fast-locking knurled  
nut, Knurled



UCF\_SS  
Stainless steel flanged  
bearing, Stainless  
steel



SH0  
Parallel axis helical  
gear, Machined plastic  
(delrin)

## Complementary products



PTA50ssEB  
Articulated foot with  
sheet metal base  
Ø50, Articulated foot



PTA80ssEB  
Articulated foot with  
sheet metal base  
Ø80, Articulated foot



PTA100ssEB  
Articulated foot with  
sheet metal base  
Ø100, Articulated foot



PAMF100EB  
Articulated foot with  
sheet metal base  
Ø100, Articulated foot