



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PAMF80

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

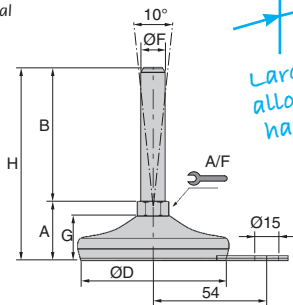

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price		-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	36,75 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	38,83 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	37,24 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	39,90 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	42,53 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	42,53 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	45,16 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	49,11 €

 
*Within the limits of available stock - Dimensions in mm

Our other products



NSKB

Drylin® Rail end cap,
Rail end cap



BETA

Hitch pin, Hitch



UTKswrr

V shaped channel
UtiliTrak®, V rail



MDB_MTB

Moulded plastic bevel
gear (nylon), 3:1



PDR-RD

Mounting feet with
integrated castors,
Offset castor



CHTRB

Single and dual
output gearboxes, Up
to 87,3 Nm



RIMple

Locking castor, with
mounting plate



CLB_M

Die cast zinc clamping
lever - female, Zamak



PCS50K

Chain sprocket with
hardened teeth,



CHAE4080PA

Symetrical decorative
screwed hinge,



T5-10ECO

T type timing pulley,
Economy range - T5



MDB_MTB

Moulded plastic bevel
gear (nylon), 3:1

Complementary products



PTA50ssEB

Articulated foot with
sheet metal base
Ø50, Articulated foot



PTA80ssEB

Articulated foot with
sheet metal base
Ø80, Articulated foot



PTA100ssEB

Articulated foot with
sheet metal base
Ø100, Articulated foot



PAMF100EB

Articulated foot with
sheet metal base
Ø100, Articulated foot