



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PAMF80

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

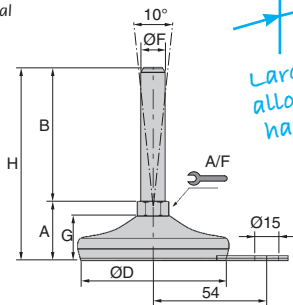

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------------|----|-----|------|------|------------|
| Disc. Price | | -5% | -10% | -15% | On request |

| Part N° | ØD | ØF | B | A | A/F | G | H | Static load(N) | Price per unit 1 to 5 |
|------------------|----|-----|-----|----|-----|----|-----|----------------|-----------------------|
| PAMF80-12-100/EB | 80 | M12 | 100 | 35 | 14 | 25 | 135 | 10000 | 36,75 € |
| PAMF80-12-150/EB | 80 | M12 | 150 | 35 | 14 | 25 | 185 | 10000 | 38,83 € |
| PAMF80-16-75/EB | 80 | M16 | 75 | 35 | 13 | 25 | 110 | 10000 | 37,24 € |
| PAMF80-16-125/EB | 80 | M16 | 125 | 35 | 13 | 25 | 160 | 10000 | 39,90 € |
| PAMF80-16-175/EB | 80 | M16 | 175 | 35 | 13 | 25 | 210 | 10000 | 42,53 € |
| PAMF80-20-100/EB | 80 | M20 | 100 | 38 | 17 | 25 | 138 | 10000 | 42,53 € |
| PAMF80-20-150/EB | 80 | M20 | 150 | 38 | 17 | 25 | 188 | 10000 | 45,16 € |
| PAMF80-20-200/EB | 80 | M20 | 200 | 38 | 17 | 25 | 238 | 10000 | 49,11 € |

*Within the limits of available stock - Dimensions in mm

Our other products



M0

Worm and wheel set,
Bronze



D19 D29

Compression springs
in metre lengths, by
the metre



RT25

Self-centering flanged
locking assembly,
Medium/high torque




NSR

Adjustable clamp,
Adjustable



PP35

 Worm and wheel gear
reducer, from 2.20 to
4.10 Nm



PRF LIS

Door seal for
aluminium profile,
Black NBR



M1

Worm and wheel set,
Non hardened steel



VDS

Sliding lock
adjustment system,
Sliding lock for oblong
hole



CHAE6555

Decorative screwed
hinges, Aluminium



CHAK

Hi-Klik™ indent
hinge, Hi-Klik™ -



ECF

Well nut, Elastomer



PHTss

Carrying handle, Up to
250 °C

Complementary products



PTA50ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA80ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA100ssEB

Articulated foot with
sheet metal base,
Articulated foot



PAMF100EB

Articulated foot with
sheet metal base,
Articulated foot