



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PAMF80

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

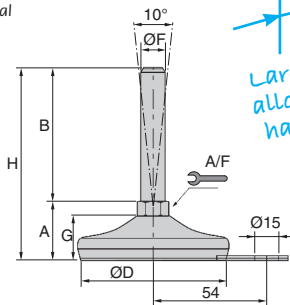

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price		-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	36,75 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	38,83 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	37,24 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	39,90 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	42,53 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	42,53 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	45,16 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	49,11 €

*Within the limits of available stock - Dimensions in mm

Our other products



PDR-RD
Mounting feet with
integrated castors,
Offset castor



T2
T type timing belt,
T2.5 Steel cored
polyurethane



CHC
Socket headed screw,
Steel class 12.19



LRM2
Cylindrical bronze nut,
Bronze - 2 threads



PRESSHR
Manual workbench
press, Force up to
500kg



WINGbrEcrou
Manually tightened
wing nut DIN315,
Brass DIN 315



CHB
Worm and wheel gear
reducer, up to 73 Nm



SNG
Stainless/Polymer
pillow block bearing,
Cast iron - Split pillow



CCL
Standard wire
thimble, Steel



EMR
Fast-locking knurled
nut, Knurled



UCF_SS
Stainless steel flanged
bearing, Stainless
steel



SH0
Parallel axis helical
gear, Machined plastic
(delrin)

Complementary products



PTA50ssEB
Articulated foot with
sheet metal base
Ø50, Articulated foot



PTA80ssEB
Articulated foot with
sheet metal base
Ø80, Articulated foot



PTA100ssEB
Articulated foot with
sheet metal base
Ø100, Articulated foot



PAMF100EB
Articulated foot with
sheet metal base
Ø100, Articulated foot