

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel


Usage

- The threaded shaft is free to rotate
- A nut under the mounting base allows both rotation and angular inclination ($\pm 4^\circ$) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.
- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

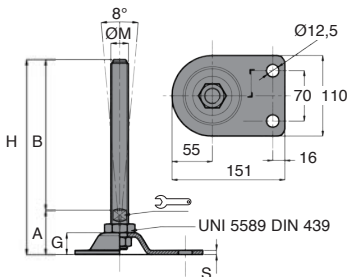

Mounting bracket

Blind hole

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØM	B	S	A	SW	G	H	Static load (N)	Price each 1 to 5
PARF110-16-150	M16	150	4	41	17	19	191	25000	19,01 €
PARF110-16-200	M16	200	4	41	17	19	241	25000	20,06 €
PARF110-20-150	M20	150	4	42	17	19	192	25000	21,31 €
PARF110-20-200	M20	200	4	42	17	19	242	25000	23,07 €
PARF110-24-150	M24	150	4	43	20	19	193	30000	25,28 €
PARF110-24-200	M24	200	4	43	20	19	243	30000	27,86 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

Our other products



WINGbr

Wing screw, hand tightened DIN316, Brass DIN 316



TFR

Rigid manual tensioner, Fixed



GLB

Small 6 lobe threaded handle - female, Technopolymer - Stainless steel



SHTP

Drylin® Linear table, Economy range



SBRtool

Chain tool, Drive chain maintenance tools



PPG

Indexing plunger with flange, With horizontal mounting flange



BOX-TOR-G

Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



BABS

630 Stainless steel compact ball pin, Hardened stainless steel



PITAss

Locking bolt, with T handle




PTAF100-PAMF100

Articulated fixable foot with pressed base Ø100, Ø 100



M2

Worm and wheel set, Hardened steel

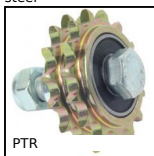

PTR

Idler chain sprocket, For standard applications

Complementary products



SPIT

Floor mounting levelling plate, With anchoring point



PTAF100-PAMF100

Articulated fixable foot with pressed base Ø100, Ø 100



PARF80

Pressed steel base rigid foot, Swivelling - Ø80