

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel

Usage

- The threaded shaft is free to rotate


- A nut under the mounting base allows both rotation and angular inclination (+/-4°) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.

- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

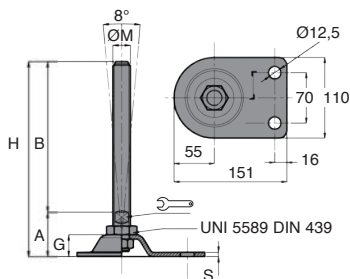

Mounting bracket

Blind hole

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------|------|-----|------|------|------------|
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | ØM | B | S | A | SW | G | H | Static load (N) | Price each 1 to 5 |
|----------------|-----|-----|---|----|----|----|-----|-----------------|-------------------|
| PARF110-16-150 | M16 | 150 | 4 | 41 | 17 | 19 | 191 | 25000 | 19,01 € |
| PARF110-16-200 | M16 | 200 | 4 | 41 | 17 | 19 | 241 | 25000 | 20,06 € |
| PARF110-20-150 | M20 | 150 | 4 | 42 | 17 | 19 | 192 | 25000 | 21,31 € |
| PARF110-20-200 | M20 | 200 | 4 | 42 | 17 | 19 | 242 | 25000 | 23,07 € |
| PARF110-24-150 | M24 | 150 | 4 | 43 | 20 | 19 | 193 | 30000 | 25,28 € |
| PARF110-24-200 | M24 | 200 | 4 | 43 | 20 | 19 | 243 | 30000 | 27,86 € |

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

289

Our other products



Arm with rotating handle, Square bore



HEAVY DUTY spur gear, Steel 35NCD6



Adjustable Stainless steel cam lever, Male



Adjustable cell support, Adjustable



Worm and wheel set, Machined plastic (delrin)



Drylin R® linear bearing housing, Closed - Slim



Plastic sprocket, 12.7mm (DIN 08B-1)



Reaction arm, CHM and CHMR gear reducers reaction arm



Technopolymer clamping lever - female, Plastic



Flexible drive shaft, Masterflex® Steel, with PVC casing



Manually operated gearbox, Bevel



Doorstop for aluminium profile, Swing door stop

Complementary products



Floor mounting levelling plate, With anchoring point



Articulated fixable foot with pressed base Ø100, Ø 100



Pressed steel base rigid foot, Swivelling - Ø80