

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel

Usage

- The threaded shaft is free to rotate


- A nut under the mounting base allows both rotation and angular inclination (+/-4°) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.

- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

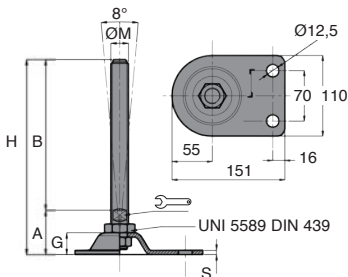

Mounting bracket

Blind hole

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØM	B	S	A	SW	G	H	Static load (N)	Price each 1 to 5
PARF110-16-150	M16	150	4	41	17	19	191	25000	19,01 €
PARF110-16-200	M16	200	4	41	17	19	241	25000	20,06 €
PARF110-20-150	M20	150	4	42	17	19	192	25000	21,31 €
PARF110-20-200	M20	200	4	42	17	19	242	25000	23,07 €
PARF110-24-150	M24	150	4	43	20	19	193	30000	25,28 €
PARF110-24-200	M24	200	4	43	20	19	243	30000	27,86 €

Dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Our other products



BIMSS
Indexing plunger mini,
miniature - Stainless
steel



GMK17_BR
Clamp for guiding
profile, Rounded only
- single



CHAEss
Decorative hinge,
Stainless steel



CHAE4060PA
Decorative
asymmetric screwed
hinge, Polyamide



CHAR7520
Spring hinge, screwed



BOX-TOR-ORFS
Box set of Nitrile O-
rings NBR90Sh A, 7.65
x 1.78mm to 37.82 x
1.78



GCH
Linear ball slide Eco
Range, economy
range



PM4
Worm and wheel set,
Non hardened steel



G0
Steel spur gear, Steel
20NCD2



AKN
Bellows coupling
Gerwah®, from 22 to



AT10-25ECO
AT type timing pulley,
Economy range -



VRC2
Retaining clamp, dual
sided, Dual sided

Complementary products



SPIT
Floor mounting
levelling plate, With
anchoring point



PTAF100-PAMF100
Articulated fixable
foot with pressed
base Ø100, Ø 100



PARF80
Pressed steel base
rigid foot, Swivelling -
Ø80