

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel

**Usage**

- The threaded shaft is free to rotate


- A nut under the mounting base allows both rotation and angular inclination (+/-4°) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.

- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

**Advantage**

- Ideal for floor mounting robots and also increased speed of production

**Economical**

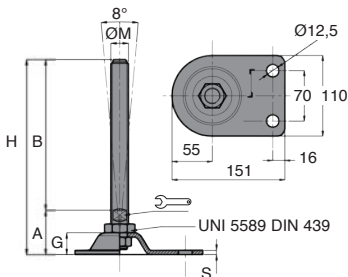

Mounting bracket

Blind hole

**DISCOUNTS**

| Qty   | 1+   | 6+  | 10+  | 15+  | 20+        |
|-------|------|-----|------|------|------------|
| Disc. | List | -5% | -10% | -15% | On request |

| Part number    | ØM  | B   | S | A  | SW | G  | H   | Static load (N) | Price each 1 to 5 |
|----------------|-----|-----|---|----|----|----|-----|-----------------|-------------------|
| PARF110-16-150 | M16 | 150 | 4 | 41 | 17 | 19 | 191 | 25000           | 19,01 €           |
| PARF110-16-200 | M16 | 200 | 4 | 41 | 17 | 19 | 241 | 25000           | 20,06 €           |
| PARF110-20-150 | M20 | 150 | 4 | 42 | 17 | 19 | 192 | 25000           | 21,31 €           |
| PARF110-20-200 | M20 | 200 | 4 | 42 | 17 | 19 | 242 | 25000           | 23,07 €           |
| PARF110-24-150 | M24 | 150 | 4 | 43 | 20 | 19 | 193 | 30000           | 25,28 €           |
| PARF110-24-200 | M24 | 200 | 4 | 43 | 20 | 19 | 243 | 30000           | 27,86 €           |

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Our other products



TBE12

Economic mini-table with trapezoidal leadscrew, 2kg



CHM30-MOT

Asynchronous AC motorgearboxes 0.09 to 0.22kW, 0.09 to 0.22kW



PP50

Worm and wheel gear reducer, from 6.50 to 12.80 Nm



BCM\_MPBT

Modular cylindrical brush, PBT polyester bristles




PM3

Worm and wheel set, Bronze



GPBSS

 Threaded spherical knob, Stainless steel 304



TC1rp

Automatic chain tensioner, With 180° guide



EX

Optional shaft for E-type gear reducers, E Gearboxes double sided ou...



TOL

Swivel head, Long



RPCplss

Fixed castor with plate, Stainless steel - Polyamide



VDSCB

Sliding lock adjustment system, Blocking wedge for



RFK58C

Hypoid gearbox - Stainless steel, up to 500 Nm

## Complementary products



SPIT

Floor mounting levelling plate, With anchoring point



PTAF100-PAMF100

Articulated fixable foot with pressed foot, Swivelling - Ø100, Ø 100



PARF80

Pressed steel base rigid foot, Swivelling - Ø80