

Articulated pressed steel feet Ø80

Ste

PARF80

Maximum load 20,000N

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel


Usage

- The threaded shaft is free to rotate
- A nut under the mounting base allows both rotation and angular inclination ($\pm 4^\circ$) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.
- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

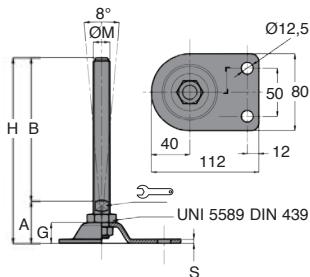

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØM	B	S	A	SW	G	H	Static load (N)	Price each 1 to 5
PARF80-16-150	M16	150	3	39,5	13	19	189,5	20000	16,51 €
PARF80-16-200	M16	200	3	39,5	13	19	239,5	20000	17,63 €
PARF80-20-150	M20	150	3	40,5	17	19	190,5	20000	18,91 €
PARF80-20-200	M20	200	3	40,5	17	19	240,5	20000	20,53 €

Dimensions in mm

Our other products



HLA19

Right angle spiro bevel gearbox, Up to 43Nm



SBS_L

Chain link, Stainless steel



PW_PWG3

Worm - precision range, Steel



PSG3

Spur gear - precision range, Case hardened steel 20NCD2



PSG05S

Spur gear - precision range, Stainless steel 316



HW_HT

Half-rail guide, Rail



LRX

Linear roller slide, Chariot - from 9410 N to 101000 N



PDM_PDV

Detectable plastic palm grip, blue thermoplastic



PITA

Locking bolt, with T handle



LWL

Linear ball slide - Stainless steel balls,



RTE

Rotex®, jaw coupling, steel



AC

Strike for toggle latch, 12,13,18 and 20mm

Complementary products



SPIT

Floor mounting levelling plate, With anchoring point



PTAF80-PAMF80

Articulated fixable foot with pressed foot Ø80, Ø 80



PARF110

Pressed steel base rigid foot, Swivelling Ø110