

Articulated pressed steel feet Ø80

Ste

PARF80

Maximum load 20,000N

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel


Usage

- The threaded shaft is free to rotate
- A nut under the mounting base allows both rotation and angular inclination ($\pm 4^\circ$) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.
- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

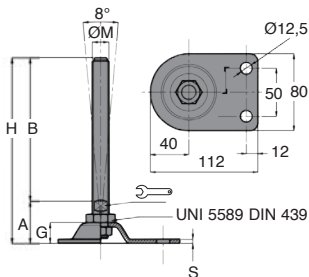

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØM	B	S	A	SW	G	H	Static load (N)	Price each 1 to 5
PARF80-16-150	M16	150	3	39,5	13	19	189,5	20000	16,51 €
PARF80-16-200	M16	200	3	39,5	13	19	239,5	20000	17,63 €
PARF80-20-150	M20	150	3	40,5	17	19	190,5	20000	18,91 €
PARF80-20-200	M20	200	3	40,5	17	19	240,5	20000	20,53 €

Dimensions in mm

Our other products



PCH
Knob for gripping,
Mushroom



VELM6
Screw-on base for
hook-and-loop strip,
Polyamide



PRES5HR
Manual workbench
press, Force up to
500kg



GET-AL
Jaw coupling,
economy range,
Aluminium



CHML50
Worm and wheel gear
reducer, up to 107
Nm - Integrated
torque limiter



NCT
Square tube
connector, Fixed
angle



BSM
Spring plunger with
internal hexagonal
socket, steel body and
pin



UGH32
H Type Guide units,
For Ø32 actuators



PDD
Actuating plunger,
Non-rotating detector



RURp
Fixed castor with
plate, Polyurethane -



VTH
Hexagonal headed
bolts, Steel class 8.8



RBN
Wheel, Rubber tyre -
Polypropylene rim

Complementary products



SPIT
Floor mounting
levelling plate, With
anchoring point



PTAF80-PAMF80
Articulated fixable
foot with pressed
foot base Ø80, Ø 80



PARF110
Pressed steel base
rigid foot, Swivelling
Ø110