

Articulated pressed steel feet Ø80

Ste

PARF80

Maximum load 20,000N

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel


Usage

- The threaded shaft is free to rotate
- A nut under the mounting base allows both rotation and angular inclination ($\pm 4^\circ$) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.
- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

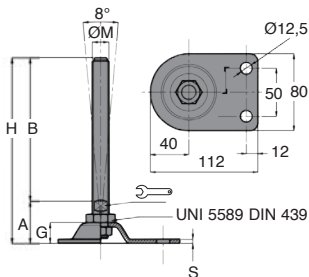

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØM	B	S	A	SW	G	H	Static load (N)	Price each 1 to 5
PARF80-16-150	M16	150	3	39,5	13	19	189,5	20000	16,51 €
PARF80-16-200	M16	200	3	39,5	13	19	239,5	20000	17,63 €
PARF80-20-150	M20	150	3	40,5	17	19	190,5	20000	18,91 €
PARF80-20-200	M20	200	3	40,5	17	19	240,5	20000	20,53 €

Dimensions in mm

Our other products



RFV50
Stainless steel worm and wheel gearbox, up to 80 Nm



BMF
Knurled knob - female, Knurled - blind



PSG35
Spur gear - precision range, Stainless steel 303



PO
Pull handle - Multi-sector, Tapped recessed insert



PRF1932
Standard aluminium profile, 19 x 32 mm



DOG316
Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



BSM
Spring plunger with internal hexagonal socket, steel body and pin




PSG08S
Spur gear - precision range, Stainless steel 316



CLASS
Stainless steel indexing handle -



 VTSM
Ball head screws Hygienic Design®.



PO
Pull handle - Multi-sector, Tapped



RCX-6
Spherical tilt washer - DIN6319, concave

Complementary products



SPIT
Floor mounting levelling plate, With anchoring point



PTAF80-PAMF80
Articulated fixable foot with pressed base $\varnothing 80$, $\varnothing 80$



PARF110
Pressed steel base rigid foot, Swivelling $\varnothing 110$