


- **Articulated foot**
- **Swivel: +/- 4° from vertical**
- **Materials:**
 - Base and rod: stainless steel 1.4301 (304)
 - Sole: vulcanised rubber (Shore hardness 80)
- Base Ø123mm

Uses

- Laboratory furniture
- Medical and food industries

Note

- Values for static load given at 50% of rod length. With dynamic or vibrating loads, value will be lower

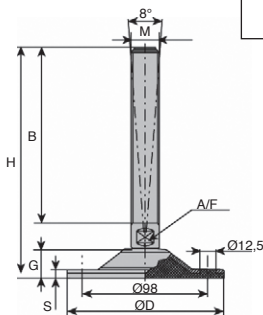

DISCOUNTS

Qty.	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	S	B	ØD	A/F	M	G	H (N)	Static load (N)	Stock*	Price each 1 to 5
PAT123-16-100/SS	7	100	123	13	M16	23,5	137	20000	✓	59,44 €
PAT123-16-150/SS	7	150	123	13	M16	23,5	187	20000	-	61,76 €
PAT123-16-175/SS	7	175	123	13	M16	23,5	212	20000	✓	64,88 €
PAT123-20-100/SS	7	100	123	17	M20	23,5	137	20000	✓	61,90 €
PAT123-20-150/SS	7	150	123	17	M20	23,5	187	20000	-	62,37 €
PAT123-20-200/SS	7	200	123	17	M20	23,5	237	20000	✓	64,22 €
PAT123-24-100/SS	7	100	123	20	M24	23,5	138	20000	✓	62,96 €
PAT123-24-150/SS	7	150	123	20	M24	23,5	188	20000	✓	64,22 €
PAT123-24-200/SS	7	200	123	20	M24	23,5	238	20000	-	66,54 €
PAT123-30-150/SS	7	150	123	26	M30	23,5	188	20000	-	72,35 €
PAT123-30-200/SS	7	200	123	26	M30	23,5	238	20000	-	79,90 €
PAT123-30-250/SS	7	250	123	26	M30	23,5	288	20000	✓	86,14 €

*Depending on availability - Dimensions in mm

Our other products



AT5P_AT10P

Connecting plate for AT type timing belts, AT5



PRF-SRA-78

Lock for aluminium profile, Quick fitting, self locking door lock



WFRM

Flanged polymer nut, Polymer (Iglidur®) - 1 thread



SHNbr

Hexagonal nut, DIN934, Brass



RBNpl

Swivel castor with double brake, Steel - rubber



PPF

Indexing plunger with flange, with drilled flange



KB_UU

Closed linear precision bearing, Precision - steel



 
HTD14M_55

HTD Heavy duty timing pulley, HTD14 Cast



PGMT

Pull handle, Steel



VAB

Ballscrew, supplied by the metre, Rolled



BPLE

Ball transfer unit push fit, Light



PFM

Fixed levelling foot, Flanged plate

Complementary products