


- **Articulated foot**
- **Swivel: +/- 4° from vertical**
- **Materials:**
 - Base and rod: stainless steel 1.4301 (304)
 - Sole: vulcanised rubber (Shore hardness 80)
- Base Ø123mm

Uses

- Laboratory furniture
- Medical and food industries

Note

- Values for static load given at 50% of rod length. With dynamic or vibrating loads, value will be lower

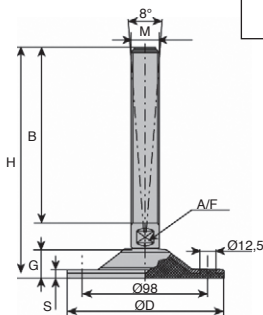

DISCOUNTS

Qty.	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	S	B	ØD	A/F	M	G	H (N)	Static load (N)	Stock*	Price each 1 to 5
PAT123-16-100/SS	7	100	123	13	M16	23,5	137	20000	✓	59,44 €
PAT123-16-150/SS	7	150	123	13	M16	23,5	187	20000	-	61,76 €
PAT123-16-175/SS	7	175	123	13	M16	23,5	212	20000	✓	64,88 €
PAT123-20-100/SS	7	100	123	17	M20	23,5	137	20000	✓	61,90 €
PAT123-20-150/SS	7	150	123	17	M20	23,5	187	20000	-	62,37 €
PAT123-20-200/SS	7	200	123	17	M20	23,5	237	20000	✓	64,22 €
PAT123-24-100/SS	7	100	123	20	M24	23,5	138	20000	✓	62,96 €
PAT123-24-150/SS	7	150	123	20	M24	23,5	188	20000	✓	64,22 €
PAT123-24-200/SS	7	200	123	20	M24	23,5	238	20000	-	66,54 €
PAT123-30-150/SS	7	150	123	26	M30	23,5	188	20000	-	72,35 €
PAT123-30-200/SS	7	200	123	26	M30	23,5	238	20000	-	79,90 €
PAT123-30-250/SS	7	250	123	26	M30	23,5	288	20000	✓	86,14 €

*Depending on availability - Dimensions in mm

Our other products



RDS
Safety washer
Hygienic Usit®,
Stainless steel




RFV63
Stainless steel worm
and wheel gearbox,
up to 152 Nm



CFF
Female rod ends DIN
ISO12240-4, Steel /
bronze



 RJUM01
Closed polymer
Drylin® R bearing,
Drylin® R



RPC
Wheel, Polyamide



M1
Worm and wheel set,
Bronze



UFX
Spare tyre UNEFLEX®
coupling, range



MACss
Stainless steel
carabiner, Stainless
steel



PRF_CH
Cable-carrier chain for
aluminium profile,



RFV40
Stainless steel worm
and wheel gearbox,



LRR
Catch-plate for latch,
Catch-plate



DOMI80
Accessories, Plate

Complementary products