


- **Articulated foot**
- **Swivel: +/- 4° from vertical**
- **Materials:**
 - Base and rod: stainless steel 1.4301 (304)
 - Sole: vulcanised rubber (Shore hardness 80)
- Base Ø123mm

Uses

- Laboratory furniture
- Medical and food industries

Note

- Values for static load given at 50% of rod length. With dynamic or vibrating loads, value will be lower

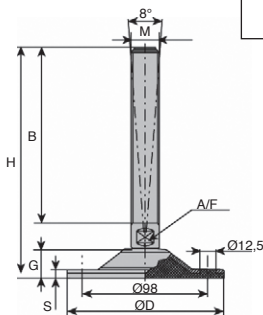

DISCOUNTS

Qty.	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	S	B	ØD	A/F	M	G	H (N)	Static load (N)	Stock*	Price each 1 to 5
PAT123-16-100/SS	7	100	123	13	M16	23,5	137	20000	✓	59,44 €
PAT123-16-150/SS	7	150	123	13	M16	23,5	187	20000	-	61,76 €
PAT123-16-175/SS	7	175	123	13	M16	23,5	212	20000	✓	64,88 €
PAT123-20-100/SS	7	100	123	17	M20	23,5	137	20000	✓	61,90 €
PAT123-20-150/SS	7	150	123	17	M20	23,5	187	20000	-	62,37 €
PAT123-20-200/SS	7	200	123	17	M20	23,5	237	20000	✓	64,22 €
PAT123-24-100/SS	7	100	123	20	M24	23,5	138	20000	✓	62,96 €
PAT123-24-150/SS	7	150	123	20	M24	23,5	188	20000	✓	64,22 €
PAT123-24-200/SS	7	200	123	20	M24	23,5	238	20000	-	66,54 €
PAT123-30-150/SS	7	150	123	26	M30	23,5	188	20000	-	72,35 €
PAT123-30-200/SS	7	200	123	26	M30	23,5	238	20000	-	79,90 €
PAT123-30-250/SS	7	250	123	26	M30	23,5	288	20000	✓	86,14 €

*Depending on availability - Dimensions in mm

Our other products



 
WFRM

Flanged polymer nut,
Polymer (Iglidur®) - 1
thread



HBM

Adjustment bushing
for half-rail guide,
Adjustment bushing



ACL-PR

Joining plate for
aluminium profile,
Right angled
connection



EBM

Steel U bolt, Steel



PM4

Worm and wheel set,
Hardened steel



DOMI50

Accessories, Clamping
lever



SRG

Adjustable latch
clamp with strike
plate, Stroke from
96mm to 121,7mm



CHMR75

Worm and wheel gear
reducer, up to 298
Nm



AT5M AT10M

AT type timing belt
per metre, AT10 Steel



HRV

V- rail guidance
Simple Select®



OP3_14_06

Reducing sleeve for
OP indicators,



M2

Worm and wheel set,
Hardened steel

Complementary products