


- **Articulated foot**
- **Swivel: +/- 4° from vertical**
- **Materials:**
 - Base and rod: stainless steel 1.4301 (304)
 - Sole: vulcanised rubber (Shore hardness 80)
- Base Ø123mm

Uses

- Laboratory furniture
- Medical and food industries

Note

- Values for static load given at 50% of rod length. With dynamic or vibrating loads, value will be lower

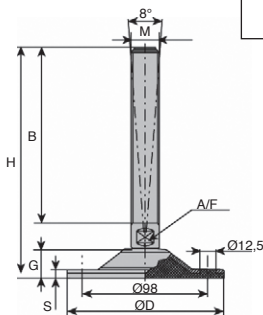

DISCOUNTS

Qty.	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	S	B	ØD	A/F	M	G	H (N)	Static load (N)	Stock*	Price each 1 to 5
PAT123-16-100/SS	7	100	123	13	M16	23,5	137	20000	✓	59,44 €
PAT123-16-150/SS	7	150	123	13	M16	23,5	187	20000	-	61,76 €
PAT123-16-175/SS	7	175	123	13	M16	23,5	212	20000	✓	64,88 €
PAT123-20-100/SS	7	100	123	17	M20	23,5	137	20000	✓	61,90 €
PAT123-20-150/SS	7	150	123	17	M20	23,5	187	20000	-	62,37 €
PAT123-20-200/SS	7	200	123	17	M20	23,5	237	20000	✓	64,22 €
PAT123-24-100/SS	7	100	123	20	M24	23,5	138	20000	✓	62,96 €
PAT123-24-150/SS	7	150	123	20	M24	23,5	188	20000	✓	64,22 €
PAT123-24-200/SS	7	200	123	20	M24	23,5	238	20000	-	66,54 €
PAT123-30-150/SS	7	150	123	26	M30	23,5	188	20000	-	72,35 €
PAT123-30-200/SS	7	200	123	26	M30	23,5	238	20000	-	79,90 €
PAT123-30-250/SS	7	250	123	26	M30	23,5	288	20000	✓	86,14 €

*Depending on availability - Dimensions in mm

Our other products



BAG
Steel Clamping collar,
Steel



FF30
Offset spur gear
reducer, from 21.50
to 83 Nm



M0
Worm and wheel set,
Machined plastic
(delrin)



CAMTH
Thermal camera for
use with smartphone,
iOS and Android



E50
Right angle helical
reducers, from 3 to 41
Nm



LVT
Miniature motorised
actuator 1A, 1 amper



KITbuh
24V DC motorisation
kit, Planetary gears



SERB
Cam latch, Cam latch



Gdal
Double universal joint
eco series, Low duty



EIM
Stainless steel U bolt,
Stainless steel



SUA4_L
Chain link, Steel



TRM
Spur round rack, Steel
- module 1-6

Complementary products