

Pressed stainless steel articulating foot **Sta**

PAT85ss

Maximum load 12.000N

- **Articulated foot**
- **Swivel: +/- 4° from vertical**
- **Materials:**
 - Base and rod: stainless steel 1.4301 (304)
 - Sole: vulcanised rubber (Shore hardness 80)


Uses

- Laboratory furniture
- Medical and food industries

Note

- Values for static load given at 50% of rod length. With dynamic or vibrating loads, value will be lower.

stainless steel

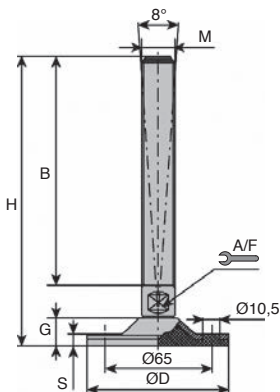

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request


Part number	S	B	ØD	A/F	M	G	H (N)	Static load (N)	Stock*	Price each 1 to 5
PAT85-16-100/SS	7	100	85	13	M16	16	130	12000	✓	47,96 €
PAT85-16-150/SS	7	150	85	13	M16	16	180	12000	-	50,45 €
PAT85-16-175/SS	7	175	85	13	M16	16	205	12000	✓	52,89 €
PAT85-20-100/SS	7	100	85	17	M20	16	130	12000	-	50,45 €
PAT85-20-150/SS	7	150	85	17	M20	16	180	12000	-	52,77 €
PAT85-20-200/SS	7	200	85	17	M20	16	230	12000	-	54,38 €

*Depending on availability - Dimensions in mm

Our other products



 VELprf
Clip-on base for hook-and-loop strip, Polyamide



Q3
Double row angular contact ball bearing, Angular contact - Steel



ZBRA
Machined plastic bevel gear , 1:1



INS
Self tapping steel insert, Steel



PF30NM
Worm and wheel gear reducer, up to 8.8 Nm



PCLA_T
Technopolymer clamping lever - male, Plastic



SUPTOOL
Installation tools for clamping hub, For hexagonal clamping hub



AT5M AT10M
AT type timing belt per metre, AT5 Steel cored polyurethane



CLA
Clamping lever Hygienic Usit® - female, Stainless steel



BABTV
Ball lock pins lockable , Stainless steel



RFVbr
Stainless steel reaction arm, Reaction arm



CLQ
12.7mm wide steel feeler strip on rolls, Feeler strip on rolls

Complementary products



PR85
Articulated foot Ø83, Ø 83