

Pressed stainless steel articulating foot **Sta**

PAT85ss

Maximum load 12.000N

- **Articulated foot**
- **Swivel: +/- 4° from vertical**
- **Materials:**
 - Base and rod: stainless steel 1.4301 (304)
 - Sole: vulcanised rubber (Shore hardness 80)


Uses

- Laboratory furniture
- Medical and food industries

Note

- Values for static load given at 50% of rod length. With dynamic or vibrating loads, value will be lower.

stainless steel

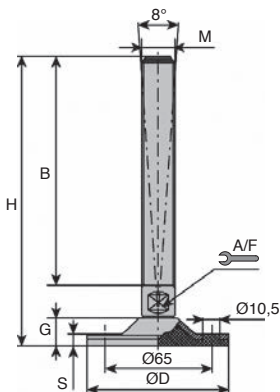

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	S	B	ØD	A/F	M	G	H (N)	Static load (N)	Stock*	Price each 1 to 5
PAT85-16-100/SS	7	100	85	13	M16	16	130	12000	✓	47,96 €
PAT85-16-150/SS	7	150	85	13	M16	16	180	12000	-	50,45 €
PAT85-16-175/SS	7	175	85	13	M16	16	205	12000	✓	52,89 €
PAT85-20-100/SS	7	100	85	17	M20	16	130	12000	-	50,45 €
PAT85-20-150/SS	7	150	85	17	M20	16	180	12000	-	52,77 €
PAT85-20-200/SS	7	200	85	17	M20	16	230	12000	-	54,38 €

*Depending on availability - Dimensions in mm


Our other products



SVR15
Screwjack with travelling nut, with moving nut



 PGT
Sliding profile, Sliding panel support



PF20NM
Worm and wheel gear reducer, up to 5 Nm



HRV
V-rail guidance Simple Select® system, Rail with carriage



BCH_SS
Mushroom headed button, M3 to M8



PW_PWG2
Worm - precision range, Stainless steel



AK
Bellows coupling Gerwah®, from 36 to 800Nm



E15
Right angle helical reducers, from 0.40 to 2.53 Nm



CHA60
Rectangular hinge, drilled or countersunk,



LACT_SS
Adjustable Stainless steel cam lever, Male



BWU
Compact precision slide, from 1510 N to 20000 N



PW_PWG05
Wheel - precision range, Bronze

Complementary products



PR85
Articulated foot Ø83, Ø 83