

Pressed stainless steel articulating foot **Sta**

PAT85ss

Maximum load 12.000N

- **Articulated foot**
- **Swivel: +/- 4° from vertical**
- **Materials:**
 - Base and rod: stainless steel 1.4301 (304)
 - Sole: vulcanised rubber (Shore hardness 80)


Uses

- Laboratory furniture
- Medical and food industries

Note

- Values for static load given at 50% of rod length. With dynamic or vibrating loads, value will be lower.

stainless steel

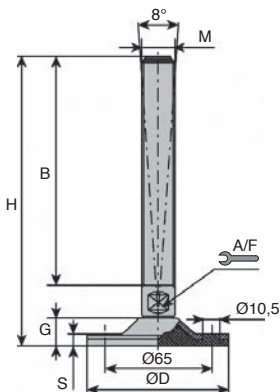

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	S	B	ØD	A/F	M	G	H (N)	Static load (N)	Stock*	Price each 1 to 5
PAT85-16-100/SS	7	100	85	13	M16	16	130	12000	✓	47,96 €
PAT85-16-150/SS	7	150	85	13	M16	16	180	12000	-	50,45 €
PAT85-16-175/SS	7	175	85	13	M16	16	205	12000	✓	52,89 €
PAT85-20-100/SS	7	100	85	17	M20	16	130	12000	-	50,45 €
PAT85-20-150/SS	7	150	85	17	M20	16	180	12000	-	52,77 €
PAT85-20-200/SS	7	200	85	17	M20	16	230	12000	-	54,38 €

*Depending on availability - Dimensions in mm

Our other products



P40
Worm and wheel gear reducer, up to 18 Nm



HRV
V-rail guidance Simple Select® system, Rail with carriage



IN2
Internal gear, Steel 20NCD2



SHW
Plain washer, A2 Stainless steel



TAC_SS
Stainless steel rigging screw (hook/eye), Stainless steel



BCA
Steel splined collar, Steel



LVT
Miniature motorised actuator 4A, 4 amperes



BCM_TP
Modular cylindrical brush, Tampico bristles



GGP
Male wing knob, Technopolymer with brass spindle



TBE16
Economic mini-table with trapezoidal leadscrew, 5kg



UTKswc
Utilitrac® 3 wheels carriage, Series V precision steel wheel



SDB
Locking bolt support bracket, Mounting holes at 90° to locating bolt

Complementary products



PR85
Articulated foot Ø83, Ø 83