



Fixed anti-vibration foot mount

For loads up to 35,000 N

PAV


- Adjustable anti-vibration floor mount
- Fine thread for an accurate level
- Materials:
 - Body: Chromed sheet steel
 - Thread: Chromed steel
 - Base: Rubber NBR 80 shore

Applications

- Machine tools, presses, injection machines, compressors.

Info

- Supplied with 1 nut and 1 washer

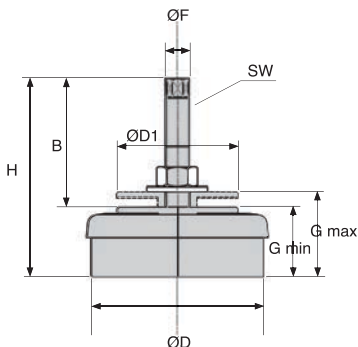

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØF	B	ØD1	SW	G	H	Max load		Price each 1 to 5
								Dynamic (N)	Static (N)	
PAV80-M12C	80	M12x1,25	87	60	8	40-50	136	2500	5000	35,71 €
PAV120-M16C	120	M16x1,5	93	80	9	45-58	150	4000	10000	60,19 €
PAV160-M20C	160	M20x1,5	125	100	12	53-65	190	9000	20000	99,48 €
PAV200-M20C	200	M20x1,5	125	130	12	69-82	207	15000	35000	136,72 €

Dimensions in mm

Our other products



IGBSz

Cylindrical ballscrew nut, Cylindrical leadscrew nut



CAP882

Flexible slat top chain acetal, Large range 882



APB_T

Adjusting rod for clamp - Female, Bored



GSI

Stainless steel gas spring, Stainless steel



RAGFLOW

Floway2® roller track, Roller track



BABPass

Hardened stainless steel ball pin with ring, With grip ring



HTD5M-BAR

HTD type tooth bar stock, HTD5



 
LC

Friction clutch, 190 to 1800 Nm



B_ECO

Eco. range steel bevel gear, 1:1



PF30NM

Worm and wheel gear reducer, up to 8.8 Nm



EAR

Bearing locknut, Self locking locknut - nylon



ATZY

Diabolo shaped elasto mount, Steel

Complementary products