


Plastic ball bearing



PBGL SING
PBss

Corrosion-resistant

- Radial contact ball bearing
- Conforms to DIN 625
- Resistant to chemicals
- Light-weight
- Working temp. up to +100°C
- No lubrication required
- Materials:
Rings: Polyoxymethylene
Ball bearings: Glass or stainless steel
Cage: Nylon

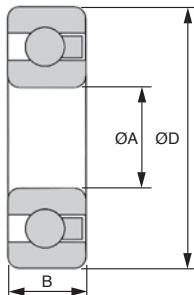

GL:
Glass balls



SS:
Stainless steel balls

Advantages

- No maintenance required

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number		ØA	ØD	B	Max speed (rpm)	Static load (daN)	Dynamic load (daN)	Price each 1 to 5	
Glass balls	Stainless steel balls							Glass balls	Stainless steel balls
PB623/GL	PB623/SS	3	10	4	4500	3,0	4,5	12,93 €	12,64 €
PB624/GL	PB624/SS	4	13	5	3600	4,0	6,0	12,42 €	12,15 €
PB625/GL	PB625/SS	5	16	5	3050	4,5	6,5	10,55 €	10,31 €
PB626/GL	PB626/SS	6	19	6	2600	5,0	7,0	10,51 €	10,20 €
PB6000/GL	PB6000/SS	10	26	8	1900	9,0	13,0	12,57 €	12,25 €
PB6001/GL	PB6001/SS	12	28	8	1750	11,0	16,0	12,59 €	12,33 €
PB6002/GL	PB6002/SS	15	32	9	1550	13,0	19,0	13,06 €	12,75 €
PB6004/GL	PB6004/SS	20	42	12	1200	20,0	30,0	17,62 €	17,16 €
PB6005/GL	PB6005/SS	25	47	12	1050	24,0	36,0	19,11 €	18,62 €
PB6006/GL	PB6006/SS	30	55	13	900	28,0	42,0	25,89 €	25,26 €
PB6007/GL	PB6007/SS	35	62	14	800	32,0	48,0	40,97 €	39,99 €
PB607/GL	PB607/SS	7	19	6	2600	4,0	6,0	9,94 €	9,71 €
PB608/GL	PB608/SS	8	22	7	2200	5,5	8,0	10,83 €	10,55 €
PB6200/GL	PB6200/SS	10	30	9	1650	13,0	17,0	11,76 €	11,46 €
PB6201/GL	PB6201/SS	12	32	10	1550	15,0	22,0	13,50 €	On request

Dimensions in mm

**Without
lubrication,
lighter**

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number					Max	Static	Dynamic	Price each 1 to 5	
Glass balls	Stainless steel balls	ØA	ØD	B	speed (rpm)	load (daN)	load (daN)	Glass balls	Stainless steel balls
PB607/GL	PB607/SS	7	19	6	2600	4.0	6.0	9,94 €	9,71 €
PB608/GL	PB608/SS	8	22	7	2200	5.5	8.0	10,83 €	10,55 €
PB609/GL	PB609/SS	9	24	7	2050	6.0	9.0	11,73 €	11,42 €
PB6200/GL	PB6200/SS	10	30	9	1850	13.0	17.0	11,78 €	11,46 €
PB6201/GL	PB6201/SS	12	32	10	1550	15.0	22.0	13,50 €	13,20 €
PB6202/GL	PB6202/SS	15	35	11	1400	17.0	25.0	15,79 €	15,41 €
PB6203/GL	PB6203/SS	17	40	12	1250	22.0	32.0	16,62 €	16,19 €
PB6204/GL	PB6204/SS	20	47	14	1050	27.0	42.0	20,75 €	20,31 €
PB6205/GL	PB6205/SS	25	52	15	950	32.0	48.0	24,43 €	23,84 €
PB6206/GL	PB6206/SS	30	62	16	800	36.0	55.0	39,17 €	38,15 €
PB6207/GL	PB6207/SS	35	72	17	700	41.0	62.0	On request	On request
PB6208/GL	PB6208/SS	40	80	18	625	44.0	66.0	On request	69,88 €
PB6209/GL	PB6209/SS	45	85	19	580	47.0	72.0	78,04 €	On request
PB6210/GL	PB6210/SS	50	90	20	550	54.0	77.0	98,00 €	On request
PB6211/GL	PB6211/SS	55	100	21	500	60.0	80.0	On request	On request
PB6212/GL	PB6212/SS	60	110	22	450	63.0	88.0	On request	On request
PB6300/GL	PB6300/SS	10	35	11	1400	19.0	28.0	16,39 €	16,01 €
PB6301/GL	PB6301/SS	12	37	12	1300	21.0	31.0	16,53 €	16,15 €
PB6302/GL	PB6302/SS	15	42	13	1200	26.0	37.0	20,45 €	19,93 €
PB6303/GL	PB6303/SS	17	47	14	1050	30.0	45.0	21,76 €	On request
PB6304/GL	PB6304/SS	20	52	15	950	35.0	53.0	25,29 €	24,66 €
PB6305/GL	PB6305/SS	25	62	17	725	40.0	60.0	39,80 €	38,77 €
PB6306/GL	PB6306/SS	30	72	19	675	46.0	70.0	64,26 €	62,63 €
PB6307/GL	PB6307/SS	35	80	21	600	49.0	75.0	On request	73,98 €
PB6309/GL	PB6309/SS	45	100	25	500	54.0	90.0	On request	On request
PB16002/GL	PB16002/SS	15	32	8	1500	13.0	19.0	12,50 €	12,21 €
PB16003/GL	PB16003/SS	17	35	8	1400	16.0	24.0	13,36 €	13,00 €
PB16004/GL	PB16004/SS	20	42	8	1150	19.0	29.0	16,99 €	16,59 €
PB16005/GL	PB16005/SS	25	47	8	1050	21.0	31.0	18,85 €	18,39 €
PB16006/GL	PB16006/SS	30	55	9	900	24.0	37.0	21,98 €	On request
PB16007/GL	PB16007/SS	35	62	9	800	29.0	43.0	On request	On request
PB16008/GL	PB16008/SS	40	68	9	750	30.0	45.0	On request	On request
PB16009/GL	PB16009/SS	45	75	10	650	33.0	50.0	On request	On request

Dimensions in mm

Our other products



SH0

Parallel axis helical gear, Steel 20NCD2




MSP19

Masterplate® glueable insert $\varnothing 19/\varnothing 20$, Cylindrical with nut



T5P_T10P

Connecting plate for T type timing belts, T5

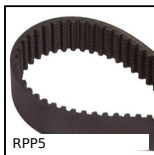

RPP5

RPP heavy duty timing belt, RPP5



HW_HT

Half-rail guide, Rail



G3-ECO

Eco range Spur gear, Steel C45



GLT3-46

Telescopic drawer,



BLHB30

Right angled gearbox, bored shafts, up to 4.47 Nm



 
LWL

Linear ball slide - Stainless steel balls, Rail - from 514 N to



CHAE4060PA

Decorative asymmetric screwed hinge, Polyamide



LAT4

 
4A motorised linear actuator, 4 amperes



SER

Magnetic doorstop for aluminium profile, Magnetic doorstop

Complementary products



PB

Plastic deep groove ball bearing, Plastic - balls material : staine...



Q6

Deep groove ball bearing, Steel