


Plastic ball bearing



PBGL SING
PBss

Corrosion-resistant

- Radial contact ball bearing
- Conforms to DIN 625
- Resistant to chemicals
- Light-weight
- Working temp. up to +100°C
- No lubrication required
- Materials:
Rings: Polyoxymethylene
Ball bearings: Glass or stainless steel
Cage: Nylon

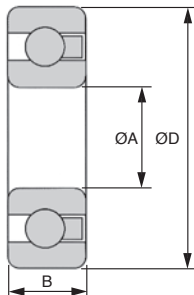

GL:
Glass balls



SS:
Stainless steel balls

Advantages

- No maintenance required

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number		ØA	ØD	B	Max speed (rpm)	Static load (daN)	Dynamic load (daN)	Price each 1 to 5	
Glass balls	Stainless steel balls							Glass balls	Stainless steel balls
PB623/GL	PB623/SS	3	10	4	4500	3,0	4,5	12,93 €	12,64 €
PB624/GL	PB624/SS	4	13	5	3600	4,0	6,0	12,42 €	12,15 €
PB625/GL	PB625/SS	5	16	5	3050	4,5	6,5	10,55 €	10,31 €
PB626/GL	PB626/SS	6	19	6	2600	5,0	7,0	10,51 €	10,20 €
PB6000/GL	PB6000/SS	10	26	8	1900	9,0	13,0	12,57 €	12,25 €
PB6001/GL	PB6001/SS	12	28	8	1750	11,0	16,0	12,59 €	12,33 €
PB6002/GL	PB6002/SS	15	32	9	1550	13,0	19,0	13,06 €	12,75 €
PB6004/GL	PB6004/SS	20	42	12	1200	20,0	30,0	17,62 €	17,16 €
PB6005/GL	PB6005/SS	25	47	12	1050	24,0	36,0	19,11 €	18,62 €
PB6006/GL	PB6006/SS	30	55	13	900	28,0	42,0	25,89 €	25,26 €
PB6007/GL	PB6007/SS	35	62	14	800	32,0	48,0	40,97 €	39,99 €
PB607/GL	PB607/SS	7	19	6	2600	4,0	6,0	9,94 €	9,71 €
PB608/GL	PB608/SS	8	22	7	2200	5,5	8,0	10,83 €	10,55 €
PB6200/GL	PB6200/SS	10	30	9	1650	13,0	17,0	11,76 €	11,46 €
PB6201/GL	PB6201/SS	12	32	10	1550	15,0	22,0	13,50 €	On request

Dimensions in mm

**Without
lubrication,
lighter**

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number					Max	Static	Dynamic	Price each 1 to 5	
Glass balls	Stainless steel balls	ØA	ØD	B	speed (rpm)	load (daN)	load (daN)	Glass balls	Stainless steel balls
PB607/GL	PB607/SS	7	19	6	2600	4.0	6.0	9,94 €	9,71 €
PB608/GL	PB608/SS	8	22	7	2200	5.5	8.0	10,83 €	10,55 €
PB609/GL	PB609/SS	9	24	7	2050	6.0	9.0	11,73 €	11,42 €
PB6200/GL	PB6200/SS	10	30	9	1850	13.0	17.0	11,78 €	11,46 €
PB6201/GL	PB6201/SS	12	32	10	1550	15.0	22.0	13,50 €	13,20 €
PB6202/GL	PB6202/SS	15	35	11	1400	17.0	25.0	15,79 €	15,41 €
PB6203/GL	PB6203/SS	17	40	12	1250	22.0	32.0	16,62 €	16,19 €
PB6204/GL	PB6204/SS	20	47	14	1050	27.0	42.0	20,75 €	20,31 €
PB6205/GL	PB6205/SS	25	52	15	950	32.0	48.0	24,43 €	23,84 €
PB6206/GL	PB6206/SS	30	62	16	800	36.0	55.0	39,17 €	38,15 €
PB6207/GL	PB6207/SS	35	72	17	700	41.0	62.0	On request	On request
PB6208/GL	PB6208/SS	40	80	18	625	44.0	66.0	On request	69,88 €
PB6209/GL	PB6209/SS	45	85	19	580	47.0	72.0	78,04 €	On request
PB6210/GL	PB6210/SS	50	90	20	550	54.0	77.0	98,00 €	On request
PB6211/GL	PB6211/SS	55	100	21	500	60.0	80.0	On request	On request
PB6212/GL	PB6212/SS	60	110	22	450	63.0	88.0	On request	On request
PB6300/GL	PB6300/SS	10	35	11	1400	19.0	28.0	16,39 €	16,01 €
PB6301/GL	PB6301/SS	12	37	12	1300	21.0	31.0	16,53 €	16,15 €
PB6302/GL	PB6302/SS	15	42	13	1200	26.0	37.0	20,45 €	19,93 €
PB6303/GL	PB6303/SS	17	47	14	1050	30.0	45.0	21,76 €	On request
PB6304/GL	PB6304/SS	20	52	15	950	35.0	53.0	25,29 €	24,66 €
PB6305/GL	PB6305/SS	25	62	17	725	40.0	60.0	39,80 €	38,77 €
PB6306/GL	PB6306/SS	30	72	19	675	46.0	70.0	64,26 €	62,63 €
PB6307/GL	PB6307/SS	35	80	21	600	49.0	75.0	On request	73,98 €
PB6309/GL	PB6309/SS	45	100	25	500	54.0	90.0	On request	On request
PB16002/GL	PB16002/SS	15	32	8	1500	13.0	19.0	12,50 €	12,21 €
PB16003/GL	PB16003/SS	17	35	8	1400	16.0	24.0	13,36 €	13,00 €
PB16004/GL	PB16004/SS	20	42	8	1150	19.0	29.0	16,99 €	16,59 €
PB16005/GL	PB16005/SS	25	47	8	1050	21.0	31.0	18,85 €	18,39 €
PB16006/GL	PB16006/SS	30	55	9	900	24.0	37.0	21,98 €	On request
PB16007/GL	PB16007/SS	35	62	9	800	29.0	43.0	On request	On request
PB16008/GL	PB16008/SS	40	68	9	750	30.0	45.0	On request	On request
PB16009/GL	PB16009/SS	45	75	10	650	33.0	50.0	On request	On request

Dimensions in mm

Our other products



 
Panamech, Multi-Beam stainless steel, Stainless steel - with clampin...



Hi-Klik™ indent hinge, Hi-Klik™ - Detent hinge



Flanged drill bushing, Steel



Pull handle - Multi-sector, Tapped recessed insert



Stainless steel bevel gear, 2:1



Worm and wheel set, Non hardened steel



 
Latch for aluminium profile, Spring operated latch



Mushroom headed button, M3 to M8



Indexing plunger with flange, with drilled flange



Worm and wheel set, Machined plastic (delrin)

 


Closed polymer Drylin® R bearing, Drylin® R



Curved tooth coupling, economy range, Steel and polyamide

Complementary products



Plastic deep groove ball bearing, Plastic - glass balls material



Deep groove ball bearing, Steel