



Single row ball bearing


Corrosion-resistant plastic

SIMG PBGL
PBSS


- **Radial contact ball bearing**
- Conforms to DIN 625
- Resistant to chemicals
- Light-weight
- Working temp. up to +100°C
- No lubrication required
- Materials:
 - Rings: Polyoxymethylene
 - Ball bearings: Glass or stainless steel
 - Cage: Nylon

Advantage

- No maintenance required

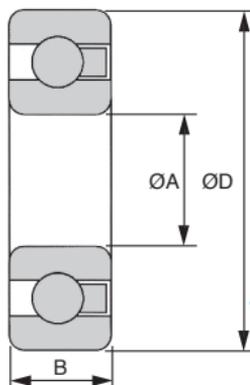


Glass ball bearings

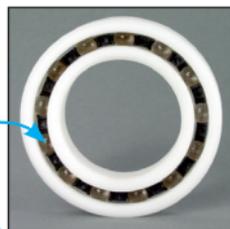

GL:
Glass balls

Stainless steel ball bearings

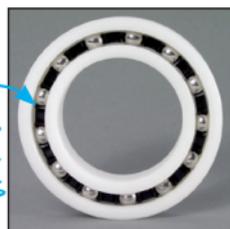

SS:
Stainless steel balls

**Without lubrication
Lighter**

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Glass balls	Stainless steel balls	ØA	ØD	B	Max speed (rpm)	Static load (daN)	Dynamic load (daN)	Price each 1 to 5	Glass balls	Stainless steel balls
PB623/GL	PB623/SS	3	10	4	4500	3,0	4,5	14,41 €	14,07 €		
PB624/GL	PB624/SS	4	13	5	3600	4,0	6,0	13,85 €	13,52 €		
PB625/GL	PB625/SS	5	16	5	3050	4,5	6,5	11,75 €	11,48 €		
PB626/GL	PB626/SS	6	19	6	2600	5,0	7,0	11,70 €	12,31 €		
PB6000/GL	PB6000/SS	10	26	8	1900	9,0	13,0	14,00 €	13,67 €		
PB6001/GL	PB6001/SS	12	28	8	1750	11,0	16,0	14,02 €	13,75 €		
PB6002/GL	PB6002/SS	15	32	9	1550	13,0	19,0	14,55 €	14,20 €		
PB6004/GL	PB6004/SS	20	42	12	1200	20,0	30,0	19,64 €	19,14 €		
PB6005/GL	PB6005/SS	25	47	12	1050	24,0	36,0	21,31 €	20,75 €		
PB6006/GL	PB6006/SS	30	55	13	900	28,0	42,0	28,88 €	28,18 €		
PB6007/GL	PB6007/SS	35	62	14	800	32,0	48,0	45,70 €	44,62 €		
PB607/GL	PB607/SS	7	19	6	2600	4,0	6,0	11,07 €	On request		
PB608/GL	PB608/SS	8	22	7	2200	5,5	8,0	12,06 €	11,75 €		
PB6200/GL	PB6200/SS	10	30	9	1650	13,0	17,0	13,09 €	On request		
PB6201/GL	PB6201/SS	12	32	10	1550	15,0	22,0	15,03 €	On request		

Dimensions in mm