
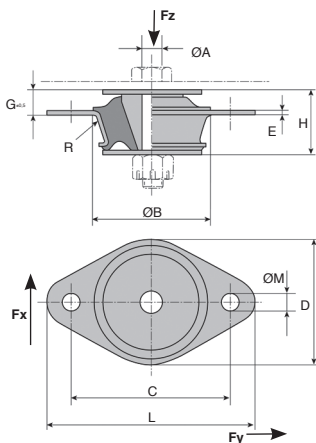
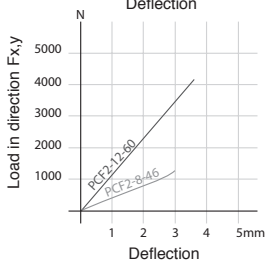
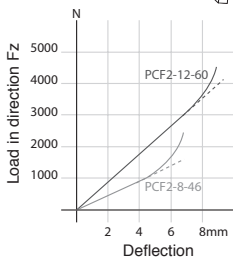
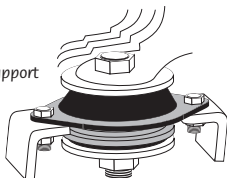


- With 2 fixing holes
- Suspension mainly by axial spring action
- Materials:
Centre: Natural rubber
(60 Shore A)
Support: steel

Uses

- Anti-vibration mounting support for motors and machines.

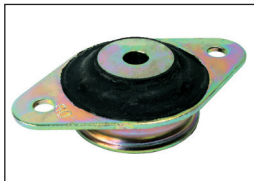

DISCOUNTS

Qty.	1+	6+	10+	20+	30+	50+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØA	ØB	L	D	C	ØM	H	G	E	R	Stock*	Price each 1 to 5
PCF2-8-46	8	46	84	50	64	6.5	27,5	12,5	2,0	R1,5	✓	17,51 €
PCF2-12-60	12	60	106	68	80	11,0	51,0	16,5	2,5	R2	✓	17,51 €

*Depending on availability

Our other products



 
PRF JL6
Lip seal for panel,
Door seal - Ø 6mm




RAS
90° ball and socket
joints DIN71802,
Stainless steel



SCR
Suction cup threaded
insert, Adaptor for
insert



 QN
Single row cylindrical
roller bearing, Free
outer ring



PRZ
Wear strip for slat top
chain, Z profile to be
clipped



RLXAC8
Free roller, Steel



PTA100
Articulated levelling
foot, pressed base
Ø100, 15000N



CHTRB
Single and dual
output gearboxes, Up
to 4,7 Nm



NT62
Spur gear coaxial
gearbox, from 6 to 18
Nm - Inline



PDD
Spring plunger, With
sensor adaptor



LC
Friction clutch, 30 to
240 Nm



CLLCLLP
Clevis components,
long version, Steel -
long range

Complementary products



PMC48_M8
Anti-vibration
machine mount, Oval
base plate



PCF4
Conical flexible
mount, Square base
plate