
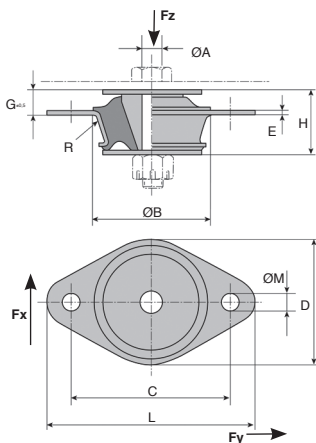
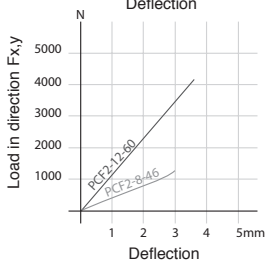
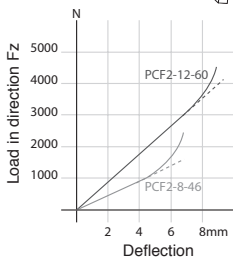
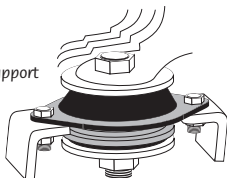


- With 2 fixing holes
- Suspension mainly by axial spring action
- Materials:
Centre: Natural rubber
(60 Shore A)
Support: steel

Uses

- Anti-vibration mounting support for motors and machines.

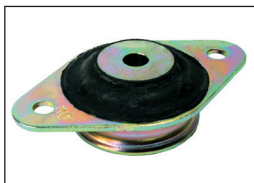

DISCOUNTS

Qty.	1+	6+	10+	20+	30+	50+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØA	ØB	L	D	C	ØM	H	G	E	R	Stock*	Price each 1 to 5
PCF2-8-46	8	46	84	50	64	6,5	27,5	12,5	2,0	R1,5	✓	17,51 €
PCF2-12-60	12	60	106	68	80	11,0	51,0	16,5	2,5	R2	✓	17,51 €

*Depending on availability

Our other products



Single chain supplied by the metre, Steel



Stainless steel rigging screw (hook/hook), Stainless steel



Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



Worm and wheel gear reducer, up to 107 Nm




HTD Heavy duty timing pulley, HTD5 Aluminium



Horizontal stirrup toggle clamp, Horizontal stirrup clamp - steel



Miniature ball transfer unit, Miniature to screw

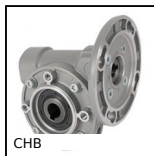

Worm and wheel gear reducer, up to 41 Nm



Open precision linear bearing, Precision -



Parallel axis helical gear, Machined plastic



Hexagonal spacer, Brass



Stainless steel knurled thumb nut, Knurled

Complementary products



Anti-vibration machine mount, Oval base plate



Conical flexible mount, Square base plate