
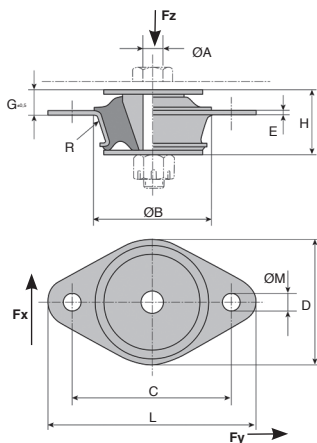
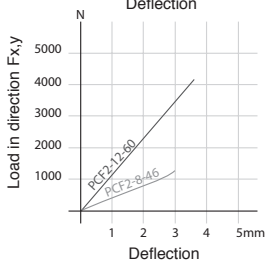
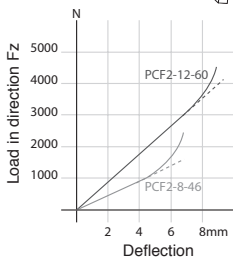
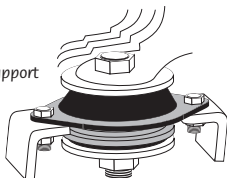


- With 2 fixing holes
- Suspension mainly by axial spring action
- Materials:
Centre: Natural rubber
(60 Shore A)
Support: steel

Uses

- Anti-vibration mounting support for motors and machines.

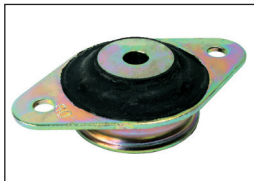

DISCOUNTS

Qty.	1+	6+	10+	20+	30+	50+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØA	ØB	L	D	C	ØM	H	G	E	R	Stock*	Price each 1 to 5
PCF2-8-46	8	46	84	50	64	6,5	27,5	12,5	2,0	R1,5	✓	17,51 €
PCF2-12-60	12	60	106	68	80	11,0	51,0	16,5	2,5	R2	✓	17,51 €

*Depending on availability

Our other products



G0

Steel spur gear, Steel 20NCD2



ZBconique

Machined plastic bevel gear, 1:1



SH0

Parallel axis helical gear, Steel 20NCD2



ACM_TRI

Manual bonnet fastener, Black rubber fastener



MEB

Moulded plastic bevel gear (nylon), 1:1



KK

Rounded end feather key, Steel



 
LQT

Mechanical catch, Quick closing catch



BHEX

Hexagonal cap, Black technopolymer



PB

Plastic deep groove ball bearing, Plastic - balls material : stainle...



PAL

Self locking counter nut, For axial locking



CHAu

Screwed hinge, 270°



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis

Complementary products



PMC48_M8

Anti-vibration machine mount, Oval base plate



PCF4

Conical flexible mount, Square base plate