
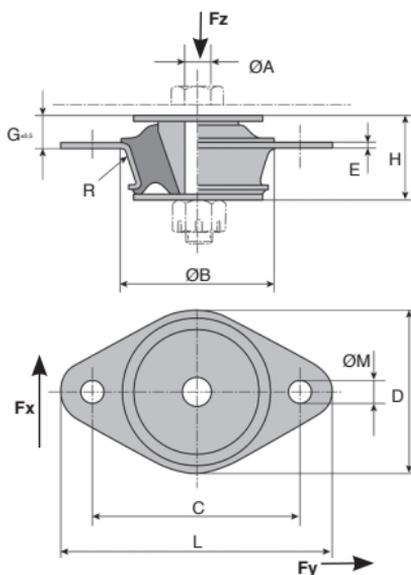
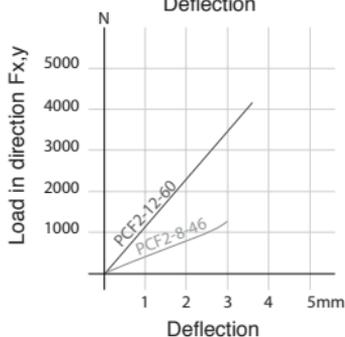
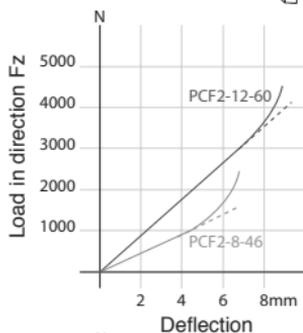


- With 2 fixing holes
- Suspension mainly by axial spring action
- Materials:
Centre: Natural rubber
(60 Shore A)
Support: steel

Uses

- Anti-vibration mounting support for motors and machines.

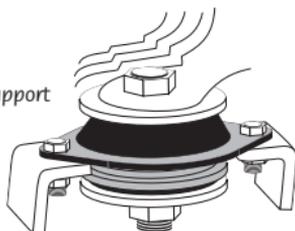

DISCOUNTS

Qty.	1+	6+	10+	20+	30+	50+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØA	ØB	L	D	C	ØM	H	G	E	R	Stock*	Price each 1 to 5
PCF2-8-46	8	46	84	50	64	6.5	27,5	12,5	2,0	R1,5	✓	17,51 €
PCF2-12-60	12	60	106	68	80	11,0	51,0	16,5	2,5	R2	✓	17,51 €

*Depending on availability

Our other products



CHT

Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW



AC144

Strike for toggle latch, 22mm




PDM_PDV

Detectable plastic palm grip, by metal detectors



FF20

Offset spur gear reducer, from 5.80 to 23 Nm

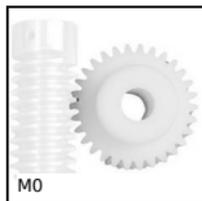

M0

Wormwheel, Machined plastic (delrin)



PAL

Self locking counter nut, For axial locking



T5P_T10P

Connecting plate for T type timing belts, T5



NCT

Square tube connector, Fixed angle



DB

Steel bevel gear, 2:1



INO

Internal gear, Steel 20NCD2



GAL_42

Guide roller for plate chain return, Without ball bearing



AT5M_AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane

Complementary products



PMC48_M8

Anti-vibration machine mount, Oval base plate



PCF4

Conical flexible mount, Square base plate