
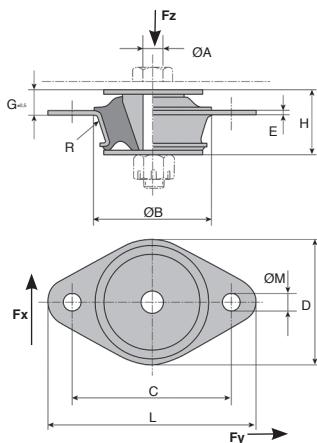
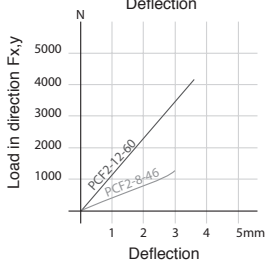
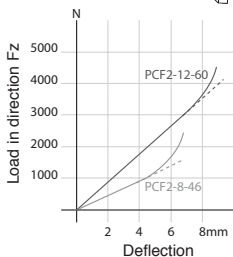
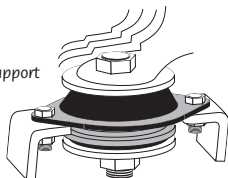


- With 2 fixing holes
- Suspension mainly by axial spring action
- Materials:
Centre: Natural rubber
(60 Shore A)
Support: steel

Uses

- Anti-vibration mounting support for motors and machines.

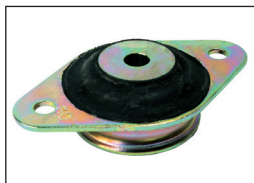

DISCOUNTS

| | | | | | | |
|-------|------|-----|------|------|------|------------|
| Qty. | 1+ | 6+ | 10+ | 20+ | 30+ | 50+ |
| Disc. | List | -5% | -10% | -15% | -20% | On request |

| Part number | ØA | ØB | L | D | C | ØM | H | G | E | R | Stock* | Price each 1 to 5 |
|-------------|-------------|-------------|-----|----|----|-------------|------|------|-----|------|--------|----------------------|
| PCF2-8-46 | 8 | 46 | 84 | 50 | 64 | 6.5 | 27,5 | 12,5 | 2,0 | R1,5 | ✓ | 17,51 € |
| PCF2-12-60 | 12 | 60 | 106 | 68 | 80 | 11,0 | 51,0 | 16,5 | 2,5 | R2 | ✓ | 17,51 € |

 
*Depending on availability

Our other products



MEB

Moulded plastic bevel gear (nylon), 1:1



BETASS

Hitch pin, Hitch



MSP23

Masterplate® glueable insert Ø23, Cylindrical Ø23 with tapped ins...



TBD

Manual leadscrew table with opposing threads, 2kg



BPHFclip

Clip for ball transfer unit, Insert clip - Installing from above



MEFC

Flanged sintered ferrous bush, Self-lubricating FP20 ferrous alloy M...



PR40

Articulated foot Ø50, Ø 50



BEK

Bearing housing for miniature ballscrew, Bearing housing



CPAS-H

Folding bracket, For heavy loads




RHTplss

High Temperature Castor, up to 200kg



SH0

 Parallel axis helical gear, Steel 20NCD2



PRF_JL6

Lip seal for panel, Door seal - Ø 6mm

Complementary products



PMC48_M8

Anti-vibration machine mount, Oval base plate



PCF4

Conical flexible mount, Square base plate