


Conical flexible mount

PCF




Square base plate

- With 4 fixing holes
- Suspension mainly by axial spring action
- Materials:
Centre: Natural rubber (60 Shore A)
Support: steel

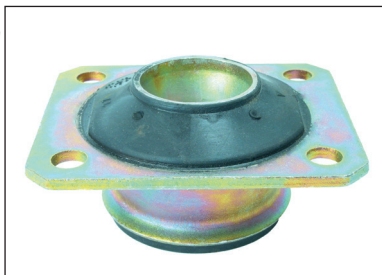

Uses

- Anti-vibration mounting support for motors and machines.

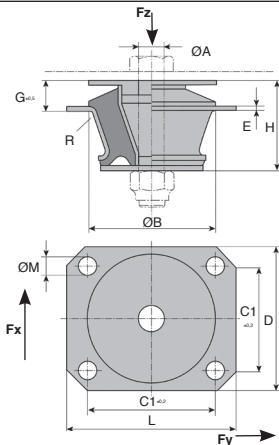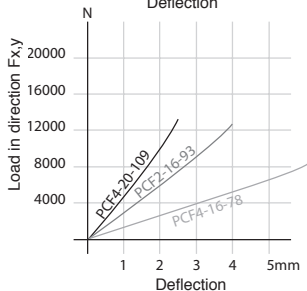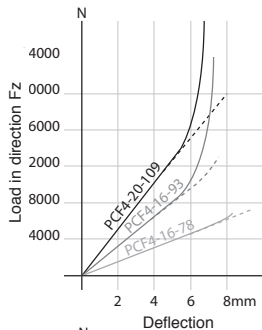

DISCOUNTS

Qty.	1+	6+	10+	20+	30+	50+
Disc.	List -5%	-10%	-15%	-20%	On request	

Part number	ØA	ØB	L	D	C1	C2	ØM	H	G	E	R	Price each 1 to 5
PCFA-16-78	16	78	107	90	80	65	11	56	19,5	3,5	R3	18,50 €
PCFA-16-93	16	93	120	100	90	74	11	81	20,0	4,3	R4	54,57 €
PCFA-20-109	20	109	140	120	112	92	11	95	23,0	4,5	R4	58,43 €

Our other products



BEAB

Knob star grip
antibacterial, Star,
anti-bacterial



ZG1

Plastic spur gear,
Machined plastic
(delrin)



BOX-TOR-A

Box set of Nitrile O-
rings in nitrile, 2.90 x
1.78mm to 28.17 x
3.53



SSHBRA

Stainless steel bevel
gear, 1,5:1 2:1 3:1



 
GAC

Latch clamp with lock,
Lockable



HSSss

Stainless steel
shoulder screw
ISO7379, Stainless
steel ISO 7379



KSM

Cylindrical steel nut,
Steel - 1 thread



PW_PWG15

Worm - precision
range, Stainless steel



S_ZZ

Deep groove ball
bearing, Stainless
steel



PSG1

Spur gear - precision
range, Case hardened
steel 20NCd2



PDD

Actuating plunger,
Non-rotating detector
shaft



AZY_SS

Stainless steel
cylindrical elastomer
mount, Stainless steel

Complementary products



PCF2

Conical flexible
mount, Oval base
plate



PMC150_M16

Anti-vibration
machine mount,
Square base plate



PMC48_M8

Anti-vibration
machine mount, Oval
base plate