

Conical flexible mount

PCF




Square base plate

- With 4 fixing holes
- Suspension mainly by axial spring action
- Materials:
Centre: Natural rubber (60 Shore A)
Support: steel



Uses

- Anti-vibration mounting support for motors and machines.

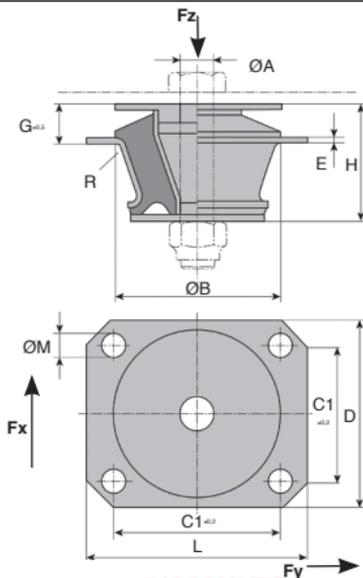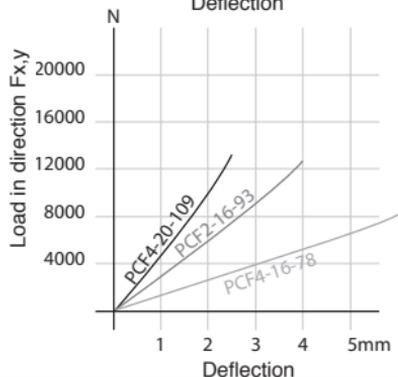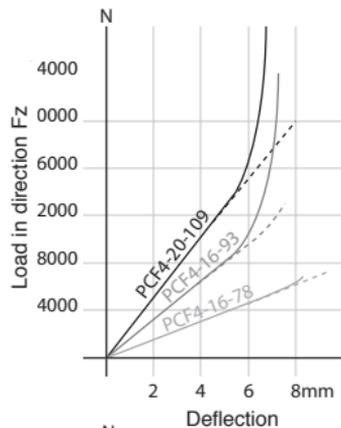

DISCOUNTS

Qty.	1+	6+	10+	20+	30+	50+
Disc.	List -5%	-10%	-15%	-20%	On request	

Part number	ØA	ØB	L	D	C1	C2	ØM	H	G	E	R	Price each 1 to 5
PCFA-16-78	16	78	107	90	80	65	11	56	19,5	3,5	R3	18,50 €
PCFA-16-93	16	93	120	100	90	74	11	81	20,0	4,3	R4	54,57 €
PCFA-20-109	20	109	140	120	112	92	11	95	23,0	4,5	R4	58,43 €

Our other products



KSM

Cylindrical steel nut,
Steel - 1 thread



BH01

Single housed
bearing, Bearing fitted
with adhesive



RFVbr

Stainless steel
reaction arm,
Reaction arm



UGH20

H Type Guide units,
For Ø20 actuators



NPR

Reflector support,



INO

Internal gear,
Machined plastic
(delrin)




PM3

Worm, Non hardened
steel



PLA

Flat magnet, Flat
magnet with threaded
hole

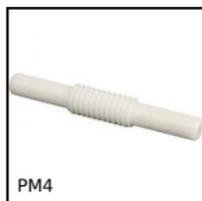

PM4

Worm, Machined
plastic (delrin)



DOMI80

Domino 80 adjustable
slide, Slide DOMILINE



ADL_F

Female eye bolt
conforms to DIN582,



PM2

Wormwheel, Bronze

Complementary products



PCF2

Conical flexible
mount, Oval base
plate



PMC150_M16

Anti-vibration
machine mount,
Square base plate



PMC48_M8

Anti-vibration
machine mount, Oval
base plate