


# Conical flexible mount

## PCF




## Square base plate

- With 4 fixing holes
- Suspension mainly by axial spring action
- Materials:  
Centre: Natural rubber (60 Shore A)  
Support: steel

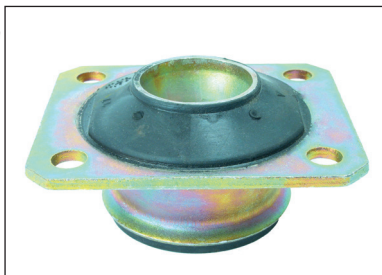

### Uses

- Anti-vibration mounting support for motors and machines.

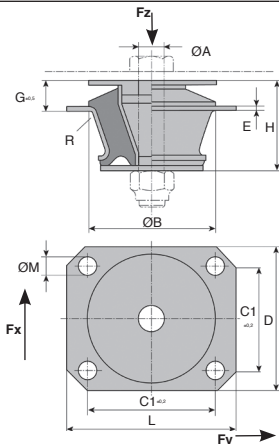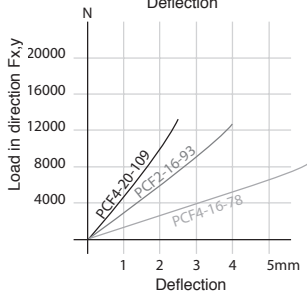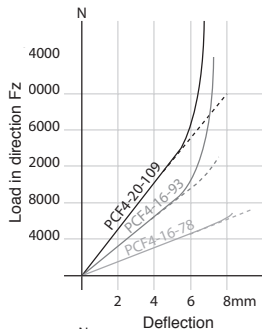

### DISCOUNTS

Qty.	1+	6+	10+	20+	30+	50+
Disc.	List -5%	-10%	-15%	-20%	On request	

Part number	ØA	ØB	L	D	C1	C2	ØM	H	G	E	R	Price each 1 to 5
PCFA-16-78	16	78	107	90	80	65	11	56	19,5	3,5	R3	18,50 €
PCFA-16-93	16	93	120	100	90	74	11	81	20,0	4,3	R4	54,57 €
PCFA-20-109	20	109	140	120	112	92	11	95	23,0	4,5	R4	58,43 €

## Our other products



DOMI50

Domino 50 adjustable slide, Slide DOMILINE 50



PRF4545

Standard stainless steel profile, 45 x 45 mm



BEAS

Star shaped anti-static handle, Star, anti-static



VCMB

Dual-thread screw wood/metal, Steel



SSG0

Stainless steel spur gear, Stainless steel 304L



VDSCB

Sliding lock adjustment system, Blocking wedge for sliding lock for ...



PCH

Knob for gripping, Mushroom



SH1

Parallel axis helical gear, Steel 20NCD2



LRR

Spring loaded latch, Spring loaded latch



HDSS

Needle roller double universal joint - Stainless steel, Heavy



BWU

Compact precision slide, from 1510 N to 10500 N



NCT

Square tube connector, Fixed angle

## Complementary products



PCF2

Conical flexible mount, Oval base plate



PMC150\_M16

Anti-vibration machine mount, Square base plate



PMC48\_M8

Anti-vibration machine mount, Oval base plate