


Conical flexible mount

PCF




Square base plate

- With 4 fixing holes
- Suspension mainly by axial spring action
- Materials:
Centre: Natural rubber (60 Shore A)
Support: steel

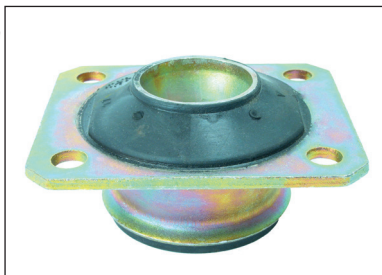

Uses

- Anti-vibration mounting support for motors and machines.

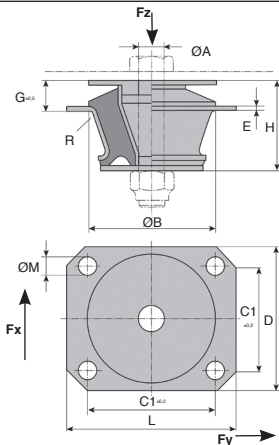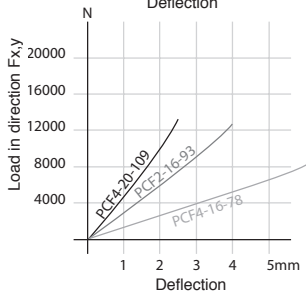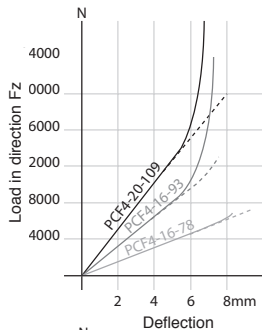

DISCOUNTS

Qty.	1+	6+	10+	20+	30+	50+
Disc.	List -5%	-10%	-15%	-20%	On request	

Part number	ØA	ØB	L	D	C1	C2	ØM	H	G	E	R	Price each 1 to 5
PCFA-16-78	16	78	107	90	80	65	11	56	19,5	3,5	R3	18,50 €
PCFA-16-93	16	93	120	100	90	74	11	81	20,0	4,3	R4	54,57 €
PCFA-20-109	20	109	140	120	112	92	11	95	23,0	4,5	R4	58,43 €

Our other products



CHTRP

Single and dual output gearboxes, Up to 87,3Nm



BOX-TOR-ORFS

Box set of Nitrile O-rings NBR90Sh A, 7.65 x 1.78mm to 37.82 x 1.78



BPFss

Pressed stainless steel flange bearing, Stainless steel



PSG1

Spur gear - precision range, Pre-hardened Steel 35NCD6



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



HFL

One way needle bearing, Needle bearing



BPQ

Quadro linear ball bearing unit, Included 4 linear ball bearings



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



CHB

Worm and wheel gear reducer, up to 73 Nm




AF

Shaft clamp with keyway, Set screw



BLH60

 Right angled gearbox, from 19 to 70 Nm



PRZ

Wear strip for slat top chain, Z profile to be filled

Complementary products



PCF2

Conical flexible mount, Oval base plate



PMC150_M16

Anti-vibration machine mount, Square base plate



PMC48_M8

Anti-vibration machine mount, Oval base plate