

Conical flexible mount

PCF




Square base plate

- With 4 fixing holes
- Suspension mainly by axial spring action
- Materials:
Centre: Natural rubber (60 Shore A)
Support: steel



Uses

- Anti-vibration mounting support for motors and machines.

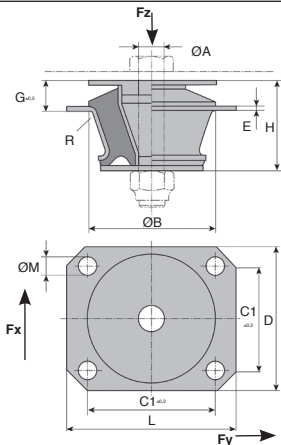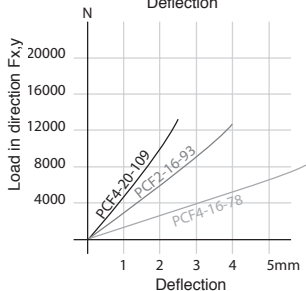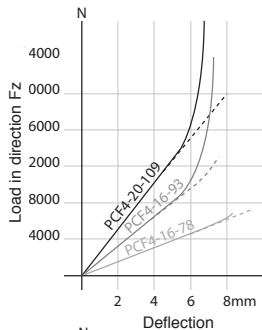

DISCOUNTS


Qty.	1+	6+	10+	20+	30+	50+
Disc.	List -5%	-10%	-15%	-20%	On request	

Part number	ØA	ØB	L	D	C1	C2	ØM	H	G	E	R	Price each 1 to 5
PCFA-16-78	16	78	107	90	80	65	11	56	19,5	3,5	R3	18,50 €
PCFA-16-93	16	93	120	100	90	74	11	81	20,0	4,3	R4	54,57 €
PCFA-20-109	20	109	140	120	112	92	11	95	23,0	4,5	R4	58,43 €

Our other products



 Stainless steel cam lever, Female



1A motorised linear actuator, 1 ampere



Steel leadscrew, Medium carbon steel - 1 thread



Clevis components, short version, Steel - short range



Compact precision slide, from 156 N to 980 N



Worm - precision range, Stainless steel



Right angled gearbox, bored shafts, up to 10.3 Nm



Knob star grip antibacterial, Star, anti-bacterial



Plastic spur gear, Machined plastic



Angular contact ball bearing, Steel



Masterplate® glueable insert



Worm and wheel gear reducer, up to 40 Nm

Complementary products

tapped i...



Conical flexible mount, Oval base plate



Anti-vibration machine mount, Square base plate



Anti-vibration machine mount, Oval base plate