

Female mushroom head handle


PCH

Technopolymer

- Handle for push/pull operations
- Material:
 - Black polyamide, matt surface finish
 - Brass insert

Info

- For larger threads, see **GPB** spherical handles (Vol 1, Page 104)

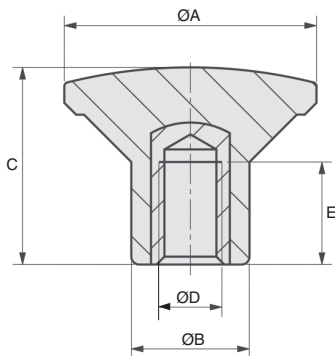

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc. Net	-5%	-10%	-15%	-20%	On request	

Part N°	ØA	ØB	C	ØD	E	Weight	Price each
						(g)	1 to 9
PCH26-M5	26	12	17	M5	8	8	1,37 €
PCH26-M6	26	12	17	M6	8	8	1,37 €
PCH32-M6	32	15	24	M6	13	13	1,88 €
PCH32-M8	32	15	24	M8	13	13	1,93 €

All dimensions in mm

HPC

WEB
04/2021

www.hpceurope.com


Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



MSP23

 Masterplate® glueable insert Ø23, Cylindrical Ø23 with threaded s...



G1

Steel spur gear, Steel 20NCD2



SLB

Indexing plunger, stainless steel



UGAC_UGET

Connection for threaded actuator rod, Connection for threaded actuat...



CHTRP

Single and dual output gearboxes, Up to 87,3 Nm



GP

Spring loaded toggle latch, With padlock-holder



GP75

Spring loaded toggle latch, Standard (GP75)



CLB_T

Die cast zinc clamping lever - male, Zamak



E50

Right angle helical reducers, from 3 to 41 Nm



BTCW

Cap for square tube to be welded, To be welded



PM4

Worm and wheel set, Machined plastic (delrin)



PLC_PLT

Magnetic stud with central hole, With central hole

Complementary products



GPB

Threaded spherical knob, Moulded thread



GPB

Threaded spherical knob, With brass insert



PGNT

Thermoplastic T handle, With threaded insert



PGNT

Thermoplastic T handle, With threaded spindle