

Female mushroom head handle


PCH

Technopolymer

- Handle for push/pull operations
- Material:
 - Black polyamide, matt surface finish
 - Brass insert

Info

- For larger threads, see **GPB** spherical handles (Vol 1, Page 104)

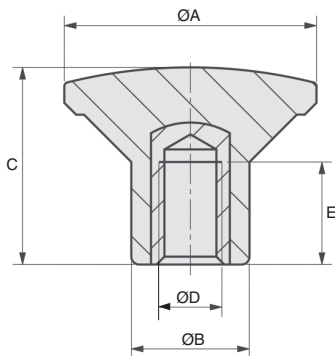

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc. Net	-5%	-10%	-15%	-20%	On request	

Part N°	ØA	ØB	C	ØD	E	Weight	Price each
						(g)	1 to 9
PCH26-M5	26	12	17	M5	8	8	1,37 €
PCH26-M6	26	12	17	M6	8	8	1,37 €
PCH32-M6	32	15	24	M6	13	13	1,88 €
PCH32-M8	32	15	24	M8	13	13	1,93 €

All dimensions in mm

 
HPC

WEB
04/2021

www.hpceurope.com


Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



BETA

 Hitch pin, Hitch



M1

Worm and wheel set,
Machined plastic
(delrin)



TCSH

Automatic chain
tensioner, With
support



CHT

Asynchronous AC
Motor, 0.55 to 1.1kW



GAL48_OMNI

Omni-directional
roller, Omni-
directional



NDS20

Double cross clamp,
Crossed



DOMI80

Accessories, Clamping
lever



BLHM70

Right angled gearbox,
up to 128 Nm



PRF4545

Standard stainless
steel profile, 45 x 45
mm



EPE

Wing nuts Hygienic
Design®, Narrow



DOG258

Motor-gearbox 12V
and 24V DC, from 12
to 15 Nm



UCFL_PBT

Stainless
steel/Polymer flanged
bearing, Polymer and
stainless steel

Complementary products



GPB

Threaded spherical
knob, Moulded thread



GPB

Threaded spherical
knob, With brass
insert