

Female mushroom head handle


PCH

Technopolymer

- Handle for push/pull operations
- Material:
 - Black polyamide, matt surface finish
 - Brass insert

Info

- For larger threads, see **GPB** spherical handles (Vol 1, Page 104)

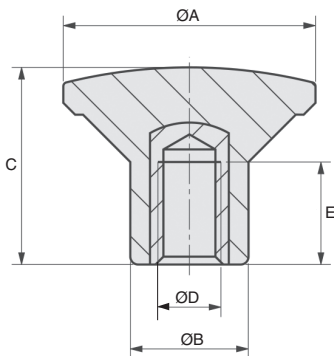

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc. Net	-5%	-10%	-15%	-20%	On request	

Part N°	ØA	ØB	C	ØD	E	Weight	Price each
						(g)	1 to 9
PCH26-M5	26	12	17	M5	8	8	1,37 €
PCH26-M6	26	12	17	M6	8	8	1,37 €
PCH32-M6	32	15	24	M6	13	13	1,88 €
PCH32-M8	32	15	24	M8	13	13	1,93 €

All dimensions in mm

HPC

WEB
04/2021

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



DKGS
Backlash free coupling Gerwah®, from 0.5 to 3Nm



M0
Worm and wheel set, Machined plastic (delrin)



PW_PWG15
Worm - precision range, Stainless steel



ACL-PLAngle
Joining plate for aluminium profile, Angle connection



HBM
Adjustment bushing for half-rail guide, Adjustment bushing



PSG25S
Spur gear - precision range, Stainless steel 303



DIL
Lever operated locking bolt, lever clamp



BOX-TOR-MAX
Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 82.14 x 3.53



SLB
Indexing plunger, steel class 5.8



RJA11_27
Sealing strip, Not clipping



PML
Solid foot mount for heavy loads, Ø 100,



BAC105
Storage bin, 8mm

Complementary products



GPB
Threaded spherical knob, Moulded thread



GPB
Threaded spherical knob, With brass insert