

Fixed cylindrical handle

Stock

PCM

Black Duroplast

Good resistance

- Fixed non-turning handle

- Material:


Black Duroplast

Advantages

- Good grip

- Easier to clean than technopolymer alternatives

- No retention of swarf in a machining environment.

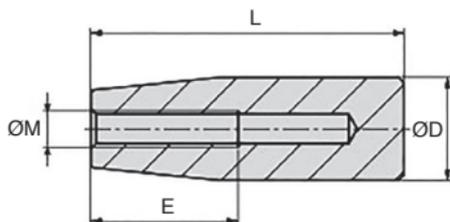

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ | 100+ | 250+ |
|-------|------|-----|------|------|------|------------|
| Disc. | List | -5% | -10% | -15% | -20% | On request |

| Part number | ØM | ØD | L | E | Weight (g) | Stock* | Price each 1 to 5 |
|--------------|-----|----|-----|----|------------|--------|-------------------|
| PCM5-13-27 | M5 | 13 | 27 | 14 | 4 | ✓ | 2,71 € |
| PCM6-13-27 | M6 | 13 | 27 | 14 | 4 | - | 2,71 € |
| PCM6-17-40 | M6 | 17 | 40 | 20 | 9 | ✓ | 2,71 € |
| PCM8-17-40 | M8 | 17 | 40 | 25 | 8 | ✓ | 2,71 € |
| PCM6-21-50 | M6 | 21 | 50 | 25 | 20 | ✓ | 3,38 € |
| PCM8-21-50 | M8 | 21 | 50 | 25 | 19 | - | 3,38 € |
| PCM10-21-50 | M10 | 21 | 50 | 25 | 18 | ✓ | 3,38 € |
| PCM6-23-55 | M6 | 23 | 55 | 25 | 25 | - | 3,71 € |
| PCM8-23-55 | M8 | 23 | 55 | 25 | 24 | - | 3,71 € |
| PCM10-23-55 | M10 | 23 | 55 | 25 | 24 | - | 3,71 € |
| PCM8-25-65 | M8 | 25 | 65 | 30 | 36 | ✓ | 3,93 € |
| PCM10-25-65 | M10 | 25 | 65 | 30 | 35 | ✓ | 3,93 € |
| PCM12-25-65 | M12 | 25 | 65 | 30 | 34 | ✓ | 3,93 € |
| PCM8-28-85 | M8 | 28 | 85 | 40 | 61 | ✓ | 5,12 € |
| PCM10-28-85 | M10 | 28 | 85 | 40 | 59 | - | 5,12 € |
| PCM12-28-85 | M12 | 28 | 85 | 40 | 56 | - | 5,12 € |
| PCM14-28-85 | M14 | 28 | 85 | 40 | 52 | ✓ | 5,12 € |
| PCM8-29-115 | M8 | 29 | 115 | 40 | 92 | - | 8,79 € |
| PCM10-29-115 | M10 | 29 | 115 | 40 | 88 | ✓ | 8,79 € |
| PCM12-29-115 | M12 | 29 | 115 | 40 | 84 | ✓ | 8,79 € |


*Depending on availability - Dimensions in mm

Good resistance

- Operating element
- Materials:
Handle - Black Duroplast
Lever - galvanised steel

Advantages

- Good grip
- Easier to clean than technopolymer alternatives
- No retention of swarf in a machining environment.

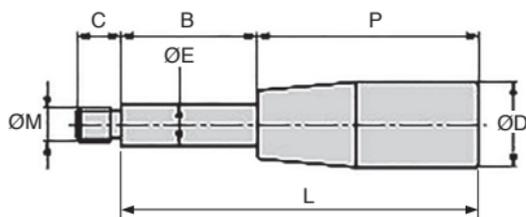**DISCOUNTS**

| Qty | 1+ | 6+ | 20+ | 50+ | 100+ | 250+ |
|-------|------|-----|------|------|------|------------|
| Disc. | List | -5% | -10% | -15% | -20% | On request |

| Part number | ØM | ØD | L | P | B | C | ØE | Weight (g) | Stock* | Price each 1 to 5 |
|---------------|-----|----|-----|----|-----|----|----|------------|--------|-------------------|
| LPCM8-17-75 | M8 | 17 | 75 | 40 | 35 | 12 | 10 | 38 | ✓ | 8,54 € |
| LPCM8-21-85 | M8 | 21 | 85 | 50 | 35 | 12 | 10 | 49 | - | 8,96 € |
| LPCM8-21-95 | M8 | 21 | 95 | 50 | 45 | 12 | 10 | 56 | ✓ | 9,18 € |
| LPCM8-21-125 | M8 | 21 | 125 | 50 | 75 | 12 | 10 | 74 | - | 10,95 € |
| LPCM8-23-130 | M8 | 23 | 130 | 55 | 75 | 12 | 10 | 80 | ✓ | 12,29 € |
| LPCM10-23-90 | M10 | 23 | 90 | 55 | 35 | 14 | 12 | 68 | - | 10,61 € |
| LPCM10-25-100 | M10 | 25 | 100 | 65 | 35 | 14 | 12 | 76 | - | 10,88 € |
| LPCM10-25-110 | M10 | 25 | 110 | 65 | 45 | 14 | 12 | 86 | ✓ | 11,57 € |
| LPCM10-25-140 | M10 | 25 | 140 | 65 | 75 | 14 | 12 | 112 | ✓ | 13,66 € |
| LPCM12-25-78 | M12 | 25 | 78 | 65 | 13 | 15 | 15 | 72 | - | 10,99 € |
| LPCM12-25-105 | M12 | 25 | 105 | 65 | 40 | 15 | 15 | 108 | - | 12,00 € |
| LPCM12-25-140 | M12 | 25 | 140 | 65 | 75 | 15 | 15 | 157 | ✓ | 13,60 € |
| LPCM12-28-98 | M12 | 28 | 98 | 85 | 13 | 15 | 15 | 96 | - | 13,98 € |
| LPCM12-28-125 | M12 | 28 | 125 | 85 | 40 | 15 | 15 | 132 | - | 14,77 € |
| LPCM12-28-160 | M12 | 28 | 160 | 85 | 75 | 15 | 15 | 181 | ✓ | 16,51 € |
| LPCM12-28-190 | M12 | 28 | 190 | 85 | 105 | 15 | 15 | 219 | - | 18,04 € |
| LPCM14-25-78 | M14 | 25 | 78 | 65 | 13 | 15 | 15 | 73 | - | 11,57 € |
| LPCM14-25-105 | M14 | 25 | 105 | 65 | 40 | 15 | 15 | 118 | - | 12,34 € |
| LPCM14-25-140 | M14 | 25 | 140 | 65 | 75 | 15 | 15 | 161 | - | 15,24 € |
| LPCM14-28-98 | M14 | 28 | 98 | 85 | 13 | 15 | 15 | 98 | - | 14,28 € |
| LPCM14-28-125 | M14 | 28 | 125 | 85 | 40 | 15 | 15 | 143 | - | 16,05 € |

*Depending on availability - Dimensions in mm