

## DIN 06B-1 Moulded Nylon PA6


### 3/8"



- Pitch 3/8" (9,525mm) (DIN 06B-1)
- Roll diameter 6.35mm
- Material  
Glass-fibre reinforced nylon PA6  
Grey colour

A\*\* : pre-bored  
hole must be  
finished

**NEW!**

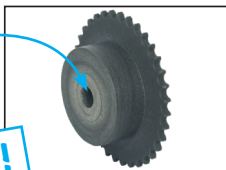


### Application

- Low coefficient of friction
- Requires little lubrication
- Quiet
- Resistant to aqueous and aggressive environments

### Info

- Rough pilot bore after moulding
- \*\*Pilot bore dimension given as a guide only
- Bore + keyway on request from 10 pieces upwards

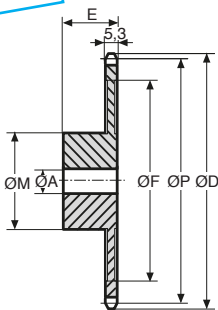

### DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	Z teeth	ØD	ØP	ØM	Pre bore			Price each 1 to 9
					ØA**	E	ØF	
PCS37-12/PA6	12	40,5	36,8	25	8	25	-	3,25 €
PCS37-13/PA6	13	43,5	39,8	28	8	25	-	3,93 €
PCS37-14/PA6	14	46,5	42,8	30	8	25	-	4,28 €
PCS37-15/PA6	15	49,5	45,8	34	8	25	-	4,85 €
PCS37-17/PA6	17	55,5	51,8	35	10	28	-	5,13 €
PCS37-18/PA6	18	58,6	54,9	40	10	28	-	5,87 €
PCS37-19/PA6	19	61,6	57,9	44	12	28	-	6,26 €
PCS37-20/PA6	20	64,6	60,9	44	12	28	-	6,79 €
PCS37-21/PA6	21	67,6	63,9	48	12	28	-	6,83 €
PCS37-25/PA6	25	79,7	76,0	57	12	28	-	7,92 €
PCS37-30/PA6	30	94,8	91,2	40	12	28	-	9,73 €
PCS37-36/PA6	36	113,0	109,2	70	16	30	-	10,18 €

Dimensions in mm

## Moulded Nylon PA6


## DIN 08B-1 1/2"



- Pitch 1/2" (12,7mm) (DIN 08B-1)
- Roller diameter 8,51mm
- Material :  
Glass-fibre reinforced nylon PA6  
Grey colour

A\*\* : pre-bored  
hole must be  
finished

**NEW !**

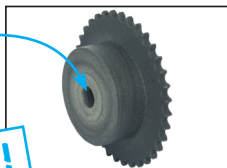


### Application

- Low coefficient of friction
- Requires little lubrication
- Quiet
- Resistant to aqueous and aggressive environments

### Info

- Rough pilot bore after moulding
- \*\*Pilot bore dimension given as a guide only
- Bore + keyway on request from 10 pieces upwards

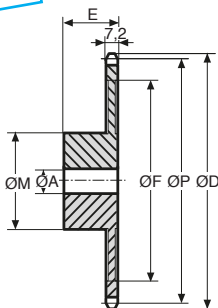

### DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	Z teeth	ØD	ØP	ØM	Pre bore ØA**	E	ØF	Price each 1 to 9
PCS50-9/PA6	9	42,0	37,13	24	10	28	-	4,74 €
PCS50-10/PA6	10	45,9	41,10	26	10	28	-	5,09 €
PCS50-12/PA6	12	54,6	49,07	32	10	28	-	5,13 €
PCS50-14/PA6	14	63,2	57,07	41	10	28	-	5,16 €
PCS50-15/PA6	15	65,9	61,09	45	10	28	-	5,20 €
PCS50-16/PA6	16	69,9	65,10	45	10	28	-	5,23 €
PCS50-17/PA6	17	74,0	69,11	50	11	28	-	6,19 €
PCS50-18/PA6	18	78,0	73,13	50	11	28	-	6,33 €
PCS50-20/PA6	20	86,0	81,19	50	11	28	-	8,48 €
PCS50-21/PA6	21	91,3	85,22	50	11	29	-	8,88 €
PCS50-28/PA6	28	118,3	113,40	60	16	29	-	11,31 €
PCS50-30/PA6	30	126,3	121,50	60	16	30	-	12,20 €
PCS50-36/PA6	36	150,6	145,70	60	16	30	125	14,25 €
PCS50-38/PA6	38	158,6	153,80	60	16	30	125	15,24 €
PCS50-40/PA6	40	166,8	161,87	60	16	30	135	17,15 €

 
Dimensions in mm

## Our other products



BCH\_SS

Mushroom headed button, M3 to M8




LVTMFC

Device for controlling limit switches, For mini-actuator LVT



ES

Bipod support base, Plastic

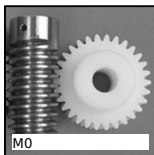

M0

Worm and wheel set, Machined plastic (delrin)



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120



CHAE6555

Decorative screwed hinge, Aluminium



BL8

Right angled gearbox, from 0.20 to 2 Nm



CLSCLP\_SS

Clevis components, short version, Stainless steel - short range



RFK58C

Hypoid gearbox - Stainless steel, up to 2 Nm



PITA

Locking bolt, with T handle



VTLB

Three-lobed knob, Thermoplastic / Brass



MRA\_SS

Stainless steel Quick link, Stainless steel

## Complementary products



PCS50

Chain sprocket - steel, 12.7mm (DIN08B-1)



PCS50SS

Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)



PCS50K

Chain sprocket with hardened teeth, 12.7mm (DIN08B-1)