

C45 steel

Pitch 1/4"


Economy range



- Pitch 1/4" (6,35mm)
- Roller diameter 3,3mm
- Material:
C45 UNI7845 steel
- **HPC are unable to modify these parts**
- **The prebore dimensions are given as a guide only and are subject to change

Accessories

- Chain part number **SUA-250/M**

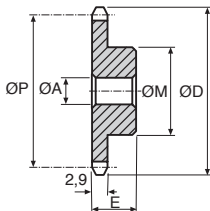

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	ØP	ØD	ØM	ØA**	E	Weight (kg)	Price each
PCS25-8	8	16,58	19,4	10	6	12	0,01	2,01 €
PCS25-9	9	18,56	21,4	11,5	6	12	0,01	2,14 €
PCS25-10	10	20,55	23,3	13	6	12	0,02	2,18 €
PCS25-11	11	22,54	25,3	15	8	13	0,02	2,22 €
PCS25-12	12	24,53	27,3	17	8	13	0,02	2,22 €
PCS25-13	13	26,53	29,3	17	8	13	0,03	2,60 €
PCS25-14	14	28,53	31,3	17	8	13	0,03	2,72 €
PCS25-15	15	30,53	33,3	20	8	13	0,04	3,06 €
PCS25-16	16	32,55	35,3	22	8	14	0,05	3,40 €
PCS25-17	17	34,55	37,3	22	8	14	0,05	4,07 €
PCS25-18	18	36,56	39,4	25	8	14	0,06	4,45 €
PCS25-19	19	38,58	41,4	25	8	14	0,06	4,79 €
PCS25-20	20	40,58	43,4	25	8	14	0,06	4,92 €
PCS25-21	21	42,60	45,4	30	8	14	0,08	5,30 €
PCS25-25	25	50,66	53,5	30	8	14	0,10	6,98 €
PCS25-28	28	56,71	59,5	30	8	16	0,12	8,50 €
PCS25-29	29	58,73	61,5	30	8	16	0,12	9,00 €
PCS25-30	30	60,75	63,6	30	8	16	0,13	9,13 €
PCS25-32	32	64,78	67,6	30	8	16	0,13	10,56 €
PCS25-33	33	66,80	69,6	30	8	16	0,14	11,06 €
PCS25-34	34	68,82	71,6	30	8	16	0,17	11,19 €
PCS25-35	35	70,84	73,6	30	8	16	0,17	11,70 €
PCS25-36	36	72,85	75,6	30	8	16	0,15	12,20 €
PCS25-37	37	74,87	77,7	30	8	16	0,18	14,30 €
PCS25-38	38	76,89	79,7	30	8	16	0,16	15,78 €
PCS25-39	39	78,91	81,7	30	8	16	0,19	17,22 €
PCS25-40	40	80,93	83,7	30	8	16	0,17	18,77 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



PLC_PLT

Magnetic stud with threaded hole, With threaded hole



5H0

Parallel axis helical gear, Machined plastic (delrin)



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



RAG-12-M8

Roller guide accessory, Anchoring system



BPHT

Ball transfer unit bolt fitting, Heavy



BPP

Pressed steel flanged bearing for light loads, Sheet steel



SA_SAKH

Housing for linear bearing, Closed - light load



BOXdHX

Boxed set of threaded dowel pins DIN7979D, Boxed set - extractable D...



BLH20

Right angled gearbox, from 0.53 to 1.77



MPB

Hexagonal spacer, Brass



VTHA

Magnetic screw with hexagonal head, Steel



HSS

Shoulder screw ISO7379, Hardened Steel class 12.9

Complementary products



SUA4

Single chain supplied by the metre, Steel



SUA4_L

Chain link, Steel