

## C45 steel

## Pitch 1/4"


**Economy range**



- Pitch 1/4" (6,35mm)
- Roller diameter 3,3mm
- Material:  
C45 UNI7845 steel
- **HPC are unable to modify these parts**
- \*\*The prebore dimensions are given as a guide only and are subject to change

### Accessories

- Chain part number **SUA-250/M**

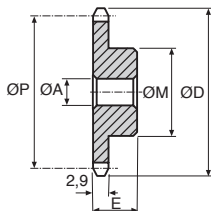

### DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	ØP	ØD	ØM	ØA**	E	Weight (kg)	Price each
PCS25-8	8	16,58	19,4	10	6	12	0,01	2,01 €
PCS25-9	9	18,56	21,4	11,5	6	12	0,01	2,14 €
PCS25-10	10	20,55	23,3	13	6	12	0,02	2,18 €
PCS25-11	11	22,54	25,3	15	8	13	0,02	2,22 €
PCS25-12	12	24,53	27,3	17	8	13	0,02	2,22 €
PCS25-13	13	26,53	29,3	17	8	13	0,03	2,60 €
PCS25-14	14	28,53	31,3	17	8	13	0,03	2,72 €
PCS25-15	15	30,53	33,3	20	8	13	0,04	3,06 €
PCS25-16	16	32,55	35,3	22	8	14	0,05	3,40 €
PCS25-17	17	34,55	37,3	22	8	14	0,05	4,07 €
PCS25-18	18	36,56	39,4	25	8	14	0,06	4,45 €
PCS25-19	19	38,58	41,4	25	8	14	0,06	4,79 €
PCS25-20	20	40,58	43,4	25	8	14	0,06	4,92 €
PCS25-21	21	42,60	45,4	30	8	14	0,08	5,30 €
PCS25-25	25	50,66	53,5	30	8	14	0,10	6,98 €
PCS25-28	28	56,71	59,5	30	8	16	0,12	8,50 €
PCS25-29	29	58,73	61,5	30	8	16	0,12	9,00 €
PCS25-30	30	60,75	63,6	30	8	16	0,13	9,13 €
PCS25-32	32	64,78	67,6	30	8	16	0,13	10,56 €
PCS25-33	33	66,80	69,6	30	8	16	0,14	11,06 €
PCS25-34	34	68,82	71,6	30	8	16	0,17	11,19 €
PCS25-35	35	70,84	73,6	30	8	16	0,17	11,70 €
PCS25-36	36	72,85	75,6	30	8	16	0,15	12,20 €
PCS25-37	37	74,87	77,7	30	8	16	0,18	14,30 €
PCS25-38	38	76,89	79,7	30	8	16	0,16	15,78 €
PCS25-39	39	78,91	81,7	30	8	16	0,19	17,22 €
PCS25-40	40	80,93	83,7	30	8	16	0,17	18,77 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Our other products



Sliding lock adjustment system, Blocking wedge for sliding lock for ...



Hose clamp, Box set of stainless steel hose clamps



Sliding lock adjustment system, Blocking wedge



Worm and wheel gear reducer, up to 41 Nm



Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW



Worm and wheel gear reducer, up to 5 Nm



Worm and wheel set, Bronze



Brass spur gear, Brass CuZn39Pb3



 
Locking bolt support bracket, Mounting



Worm and wheel set, Non hardened steel



Worm and wheel gear reducer, up to 57 Nm



4A motorised linear actuator, 4 amperes

## Complementary products



Single chain supplied by the metre, Steel



Chain link, Steel