

## C45 steel

## Pitch 1/4"


**Economy range**



- Pitch 1/4" (6,35mm)
- Roller diameter 3,3mm
- Material:  
C45 UNI7845 steel
- **HPC are unable to modify these parts**
- \*\*The prebore dimensions are given as a guide only and are subject to change

### Accessories

- Chain part number **SUA-250/M**

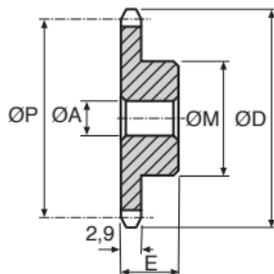

### DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	ØP	ØD	ØM	ØA**	E	Weight (kg)	Price each
PCS25-8	8	16,58	19,4	10	6	12	0,01	2,01 €
PCS25-9	9	18,56	21,4	11,5	6	12	0,01	2,14 €
PCS25-10	10	20,55	23,3	13	6	12	0,02	2,18 €
PCS25-11	11	22,54	25,3	15	8	13	0,02	2,22 €
PCS25-12	12	24,53	27,3	17	8	13	0,02	2,22 €
PCS25-13	13	26,53	29,3	17	8	13	0,03	2,60 €
PCS25-14	14	28,53	31,3	17	8	13	0,03	2,72 €
PCS25-15	15	30,53	33,3	20	8	13	0,04	3,06 €
PCS25-16	16	32,55	35,3	22	8	14	0,05	3,40 €
PCS25-17	17	34,55	37,3	22	8	14	0,05	4,07 €
PCS25-18	18	36,56	39,4	25	8	14	0,06	4,45 €
PCS25-19	19	38,58	41,4	25	8	14	0,06	4,79 €
PCS25-20	20	40,58	43,4	25	8	14	0,06	4,92 €
PCS25-21	21	42,60	45,4	30	8	14	0,08	5,30 €
PCS25-25	25	50,66	53,5	30	8	14	0,10	6,98 €
PCS25-28	28	56,71	59,5	30	8	16	0,12	8,50 €
PCS25-29	29	58,73	61,5	30	8	16	0,12	9,00 €
PCS25-30	30	60,75	63,6	30	8	16	0,13	9,13 €
PCS25-32	32	64,78	67,6	30	8	16	0,13	10,56 €
PCS25-33	33	66,80	69,6	30	8	16	0,14	11,06 €
PCS25-34	34	68,82	71,6	30	8	16	0,17	11,19 €
PCS25-35	35	70,84	73,6	30	8	16	0,17	11,70 €
PCS25-36	36	72,85	75,6	30	8	16	0,15	12,20 €
PCS25-37	37	74,87	77,7	30	8	16	0,18	14,30 €
PCS25-38	38	76,89	79,7	30	8	16	0,16	15,78 €
PCS25-39	39	78,91	81,7	30	8	16	0,19	17,22 €
PCS25-40	40	80,93	83,7	30	8	16	0,17	18,77 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Our other products



DKN  
Bellows coupling  
Gerwah®, from 0.4 to  
10Nm



MSP23  
Masterplate®  
glueable insert Ø23,  
Cylindrical Ø23 with  
threaded s...



CPAS  
Stay with safety  
catch, Opens upward



PGT  
Sliding profile, Sliding  
panel support



BH02  
Single housed bearing  
assembly, Bearing  
secured with circlips



CLLCLLP  
Clevis components,  
long version, Steel -  
long version



PRFRTR  
Cross connector for  
aluminium profile,  
Cross connector



BOX-SHNA  
Hexagonal nut -  
DIN934, Box set of  
steel nuts



METC  
Flanged sintered  
bronze bush, Self-  
lubricating sintered  
bronze



PRF\_PGN  
Door handle for  
aluminium profile,  
Handle with lock  
suitable




CHB  
Single output shaft,  
For CHB gearbox



GE\_ET\_2RS  
Spherical bushing,  
Hard chromium /  
Teflon contact with  
seals

## Complementary products

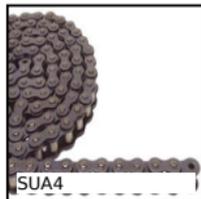

SUA4  
Single chain supplied  
by the metre, Steel



SUA4\_L  
Chain link, Steel