

# Chain sprocket **DIN 06B-1**



## Pitch 3/8"



## Steel

- Pitch 3/8" (9.525mm) (DIN 06B-1)
- Roller diameter 6.35mm
- Material: Steel C43
- HPC are unable to modify these parts


### Options

- American pitch (ASA) on request
- The prebore dimensions are given as a guide only and are subject to change
- Custom made versions available

### Accessories

- SBR-375 and SBS-375 chains

**Economy range**

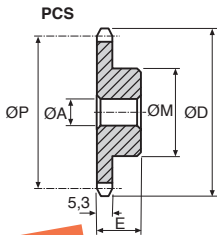

### DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	ØP	ØD	ØM	ØA	E	Stock*	Price each 1 to 5
PCS37-8	8	24,89	28,0	15	8	22	✓	1,37 €
PCS37-9	9	27,85	31,0	18	8	22	✓	1,48 €
PCS37-10	10	30,82	34,0	20	8	22	✓	1,51 €
PCS37-12	12	36,80	40,0	25	8	25	✓	2,40 €
PCS37-13	13	39,80	43,0	28	10	25	✓	2,69 €
PCS37-14	14	42,80	46,3	31	10	25	✓	3,01 €
PCS37-15	15	45,81	49,3	34	10	25	✓	3,11 €
PCS37-16	16	48,82	52,3	37	10	28	✓	3,61 €
PCS37-17	17	51,83	55,3	40	10	28	✓	4,25 €
PCS37-18	18	54,85	58,3	43	10	28	✓	4,78 €
PCS37-20	20	60,89	64,3	46	10	28	✓	5,10 €
PCS37-21	21	63,91	68,0	48	12	28	✓	5,67 €
PCS37-22	22	66,93	71,0	50	12	28	✓	6,33 €
PCS37-23	23	69,95	73,5	52	12	28	✓	6,72 €
PCS37-24	24	72,97	77,0	54	12	28	✓	6,98 €
PCS37-25	25	76,00	80,0	57	12	28	✓	7,27 €
PCS37-26	26	79,02	83,0	60	12	28	✓	8,13 €
PCS37-27	27	82,04	86,0	60	12	28	✓	8,28 €
PCS37-28	28	85,07	89,0	60	12	28	✓	8,52 €
PCS37-29	29	88,09	92,0	60	12	28	-	8,93 €
PCS37-30	30	91,12	94,7	60	12	28	✓	9,35 €
PCS37-32	32	97,17	101,3	65	14	30	✓	11,01 €
PCS37-33	33	100,20	104,3	65	14	30	-	11,54 €
PCS37-34	34	103,23	107,3	65	14	30	✓	11,57 €
PCS37-35	35	106,26	110,4	65	14	30	-	12,36 €
PCS37-36	36	109,29	113,4	70	14	30	-	12,87 €
PCS37-38	38	115,34	119,5	70	14	30	-	13,32 €
PCS37-40	40	121,40	125,5	70	14	30	✓	14,16 €

\*Depending on availability - Dimensions in mm

## Our other products



VTHbr

Hexagonal headed screw VTH - DIN933, Brass



BEAS

Star shaped anti-static handle, Star, anti-static



BDM

Pin for magnetic bush, Fast and light magnetic locking



TBD

Manual leadscrew table with opposing threads, 40kg



H2

Crossed helical gear crossed axis at 90°, Steel 20NCD2



M1

Worm and wheel set, Non hardened steel



BLH40

Right angled gearbox, from 3 to 10.30 Nm



BLH20

Right angled gearbox, from 0.53 to 1.77



Q6

Deep groove ball bearing, Steel



PMC48\_M8

Anti-vibration machine mount, Oval base plate



PRF\_PL\_9090

Joining plate for aluminium profile, Joint plate - 90x90 mm



FBL6000\_K1

Brush strip per meter PA6 fibres Ø0.2 to Ø0.3, Black polyamide 6 -...

## Complementary products



SUA4

Single chain supplied by the metre, Steel



SBS\_M

Single chain supplied by the metre, Stainless steel



PCS\_PA6

Plastic sprocket, 9.525mm (DIN 06B-1)



TCXR

Automatic chain tensioner, With steel sprocket