

Chain sprocket with **hardened teeth**

DIN06B-1  **C45 tempered steel**
3/8"

- Pitch 9.525mm (DIN06B-1)
- Roller diameter 9.35
- Materials:
 C45 steel UNI7845
 Hardened teeth 45-53HRC

Accessory

- SBR-375/M chain


Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°



Bore and keyway

2 threaded holes

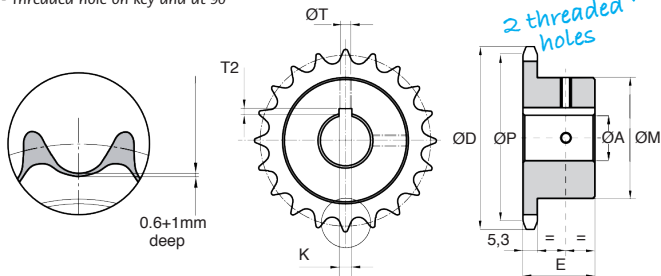

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	K			ØT	Price each
						ØA	(H9)	T2		1 to 5
PCS37-12H-12K	12	36,80	40,45	30	25	12	4	1,80	M4	5,64 €
14						5	2,30	M4	5,64 €	
15						5	2,30	M4	5,64 €	
16						5	2,30	M4	5,64 €	
PCS37-13H-12K	13	39,80	43,50	28	25	12	4	1,80	M4	6,09 €
14						5	2,30	M4	6,09 €	
15						5	2,30	M4	6,09 €	
16						5	2,30	M4	6,09 €	
PCS37-13H-18K	14	42,80	46,50	31	25	18	6	2,80	M5	6,09 €
12						4	1,80	M4	6,82 €	
14						5	2,30	M4	6,82 €	
15						5	2,30	M4	6,82 €	
PCS37-14H-12K	14	42,80	46,50	31	25	12	4	1,80	M4	6,82 €
14						5	2,30	M4	6,82 €	
15						5	2,30	M4	6,82 €	
16						5	2,30	M4	6,82 €	
PCS37-14H-18K	14	42,80	46,50	31	25	18	6	2,80	M5	6,82 €

All dimensions in mm

Part N°	Z					K				Price each 1 to 5
	Teeth	ØP	ØD	ØM	E	ØA	(H9)	T2	ØT	
PCS37-15H-14K						14	5	2,30	M4	6,94 €
PCS37-15H-15K						15	5	2,30	M4	6,94 €
PCS37-15H-16K						16	5	2,30	M4	6,94 €
PCS37-15H-18K	15	45,81	49,50	34	25	18	6	2,80	M4	6,94 €
PCS37-15H-19K						19	6	2,80	M5	6,94 €
PCS37-15H-20K						20	6	2,80	M5	6,94 €
PCS37-15H-22K						22	6	2,80	M5	6,94 €
PCS37-15H-24K						24	8	3,30	M6	6,94 €
PCS37-16H-14K										
PCS37-16H-15K						15	5	2,30	M4	7,44 €
PCS37-16H-16K						16	5	2,30	M4	7,44 €
PCS37-16H-18K	16	48,82	52,30	37	28	18	6	2,80	M5	7,44 €
PCS37-16H-19K						19	6	2,80	M5	7,44 €
PCS37-16H-20K						20	6	2,80	M5	7,44 €
PCS37-16H-22K						22	6	2,80	M5	7,44 €
PCS37-16H-24K						24	8	3,30	M6	7,44 €
PCS37-17H-14K										
PCS37-17H-15K						15	5	2,30	M4	7,88 €
PCS37-17H-16K						16	5	2,30	M4	7,88 €
PCS37-17H-18K	17	51,83	55,50	40	28	18	6	2,80	M5	7,88 €
PCS37-17H-19K						19	6	2,80	M5	7,88 €
PCS37-17H-20K						20	6	2,80	M5	7,88 €
PCS37-17H-22K						22	6	2,80	M5	7,88 €
PCS37-17H-24K						24	8	3,30	M6	7,88 €
PCS37-18H-14K										
PCS37-18H-15K						15	5	2,30	M4	8,01 €
PCS37-18H-16K						16	5	2,30	M4	8,01 €
PCS37-18H-18K	18	54,85	58,30	43	28	18	6	2,80	M5	8,01 €
PCS37-18H-19K						19	6	2,80	M5	8,01 €
PCS37-18H-20K						20	6	2,80	M5	8,01 €
PCS37-18H-22K						22	6	2,80	M5	8,01 €
PCS37-18H-24K						24	8	3,30	M6	8,01 €
PCS37-19H-15K										
PCS37-19H-16K						16	5	2,30	M4	8,70 €
PCS37-19H-18K						18	6	2,80	M5	8,70 €
PCS37-19H-19K	19	57,87	61,60	45	28	19	6	2,80	M5	8,70 €
PCS37-19H-20K						20	6	2,80	M5	8,70 €
PCS37-19H-22K						22	6	2,80	M5	8,70 €
PCS37-19H-24K						24	8	3,30	M6	8,70 €
PCS37-19H-25K						25	8	3,30	M6	8,70 €
PCS37-20H-15K										
PCS37-20H-16K						16	5	2,30	M4	9,23 €
PCS37-20H-18K						18	6	2,80	M5	9,23 €
PCS37-20H-19K	20	60,89	64,30	46	28	19	6	2,80	M5	9,23 €
PCS37-20H-20K						20	6	2,80	M5	9,23 €
PCS37-20H-22K						22	6	2,80	M5	9,23 €
PCS37-20H-24K						24	8	3,30	M6	9,23 €
PCS37-20H-25K						25	8	3,30	M6	9,23 €

Chain sprocket with **hardened teeth**

DIN06B-1  **C45 tempered steel**
3/8"

- Pitch 9.525mm (DIN06B-1)
- Roller diameter 9.35
- Materials:
 C45 steel UNI7845
 Hardened teeth 45-53HRC

Accessory

- SBR-375/M chain

Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°



Bore and keyway

2 threaded holes


DISCOUNTS

Qty	1+	6+	20+	40+
Disc.				
List	-12%	-25%		On request



Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each 1 to 5
PCS37-21H-15K						15	5	2,30	M4	9,52 €
PCS37-21H-16K						16	5	2,30	M4	9,52 €
PCS37-21H-18K						18	6	2,80	M5	9,52 €
PCS37-21H-19K	21	63,91	67,60	48	28	19	6	2,80	M5	9,52 €
PCS37-21H-20K						20	6	2,80	M5	9,52 €
PCS37-21H-22K						22	6	2,80	M5	9,52 €
PCS37-21H-24K						24	8	3,30	M6	9,52 €
PCS37-21H-25K						25	8	3,30	M6	9,52 €
PCS37-23H-15K										
PCS37-23H-16K						16	5	2,30	M4	11,40 €
PCS37-23H-18K						18	6	2,80	M5	11,40 €
PCS37-23H-19K	23	69,95	73,70	52	28	19	6	2,80	M5	11,40 €
PCS37-23H-20K						20	6	2,80	M5	11,40 €
PCS37-23H-22K						22	6	2,80	M5	11,40 €
PCS37-23H-24K						24	8	3,30	M6	11,40 €
PCS37-23H-25K						25	8	3,30	M6	11,40 €

All dimensions in mm

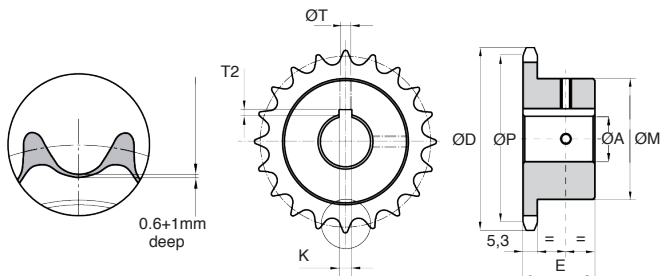

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each					
										1 to 5					
PCS37-24H-18K	24	72,97	76,70	54	28	18	6	2,80	M5	12,22 €					
PCS37-24H-19K						19	6	2,80	M5	12,22 €					
PCS37-24H-20K						20	6	2,80	M5	12,22 €					
PCS37-24H-22K						22	6	2,80	M5	12,22 €					
PCS37-24H-24K						24	8	3,30	M6	12,22 €					
PCS37-24H-25K						25	8	3,30	M6	12,22 €					
PCS37-24H-28K						28	8	3,30	M6	12,22 €					
PCS37-24H-30K						30	8	3,30	M6	12,22 €					
PCS37-25H-18K						25	76,00	79,70	57	28	18	6	2,80	M5	13,12 €
PCS37-25H-19K											19	6	2,80	M5	13,12 €
PCS37-25H-20K	20	6	2,80	M5	13,12 €										
PCS37-25H-22K	22	6	2,80	M5	13,12 €										
PCS37-25H-24K	24	8	3,30	M6	13,12 €										
PCS37-25H-25K	25	8	3,30	M6	13,12 €										
PCS37-25H-28K	28	8	3,30	M6	13,12 €										
PCS37-25H-30K	30	8	3,30	M6	13,12 €										
PCS37-27H-20K	27	82,05	85,70	60	28						20	6	2,80	M5	15,65 €
PCS37-27H-22K											22	6	2,80	M5	15,65 €
PCS37-27H-24K						24	8	3,30	M6	15,65 €					
PCS37-27H-25K						25	8	3,30	M6	15,65 €					
PCS37-27H-28K						28	8	3,30	M6	15,65 €					
PCS37-27H-30K						30	8	3,30	M6	15,65 €					
PCS37-30H-20K	30	91,12	94,80	60	30	20	6	2,80	M5	18,19 €					
PCS37-30H-22K						22	6	2,80	M5	18,19 €					
PCS37-30H-24K						24	8	3,30	M6	18,19 €					
PCS37-30H-25K						25	8	3,30	M6	18,19 €					
PCS37-30H-28K						28	8	3,30	M6	18,19 €					
PCS37-30H-30K						30	8	3,30	M6	18,19 €					

Our other products



SUPccss

Self-centering clamping hub stainless steel, With lock nut



VELM6

Screw-on base for hook-and-loop strip, Polyamide



BPMc

Stainless steel slotted spring plunger with ceramic ball tip, 303 St...



DCA

Suction cup, 1.5 bellows, nitrile




BCH_SS

Mushroom headed button, M3 to M8



HS

Hexagonal spacer, Stainless steel 303

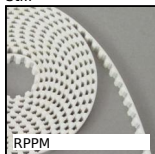

RPPM

RPP type belt per metre, RPP5 Steel cored polyurethane



FBL4004_K7

Brush strip per meter PA6 fibres Ø0.3 to Ø0.5, Black polyamide 6 -...



MO

Worm and wheel set, Machined plastic



BG

Oldham coupling, With set screw



RHTplss

High Temperature Castor, up to 200kg



KITbuh

24V DC motorisation kit, Planetary gears

Complementary products



SUA4

Single chain supplied by the metre, Steel



SUA4_L

Chain link, Steel



PCS37

Chain sprocket - steel, 9.525mm (DIN06B-1)



PCS_PA6

Plastic sprocket, 9.525mm (DIN 06B-1)