

# Stainless steel chain sprocket

## DIN 06B-1


## 304 stainless steel

# 3/8"



- Pitch 3/8" (9.525mm) (DIN 06B-1)
- Roller diameter 6.35mm
- Material:  
stainless steel AISI 304
- **We are unable to modify these parts**
- \*Pilot bore dimensions are given as a guide only and are subject to change

stainless steel

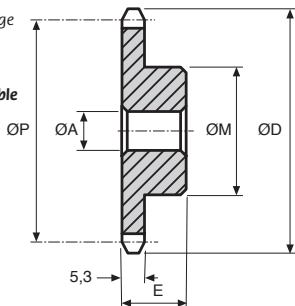

### Options

- American pitch (ASA) on request
- Custom made versions are available

### Accessories

- SBS-375 chain

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-12%	On request

Part number	Z Teeth	ØP	ØD	ØM	*Pilot bore not guaranteed ØA	E	Price each. 1 to 3
PCS37-12/SS	12	36,80	40,0	25	8	25	13,05 €
PCS37-13/SS	13	39,80	43,0	28	10	25	14,11 €
PCS37-15/SS	15	45,81	49,3	34	10	25	20,11 €
PCS37-16/SS	16	48,82	52,3	37	10	28	25,74 €
PCS37-17/SS	17	51,83	55,3	40	10	28	27,33 €
PCS37-18/SS	18	54,85	58,3	43	10	28	28,47 €
PCS37-19/SS	19	57,87	61,3	46	10	28	29,09 €
PCS37-20/SS	20	60,89	64,3	46	10	28	30,76 €
PCS37-21/SS	21	63,91	68,0	48	12	28	30,96 €
PCS37-23/SS	23	69,95	73,5	52	12	28	34,55 €
PCS37-25/SS	25	76,00	80,0	57	12	28	37,98 €
PCS37-30/SS	30	91,12	94,7	60	12	30	44,71 €

Dimensions in mm

## Our other products



MHMEP  
Arm with rotating handle, Prebored



DB  
Steel bevel gear, 2:1



CDR  
Retaining cable for ball pin, Retaining cable



BPL  
Ball transfer unit light duty, Light



AC144  
Strike for toggle latch, 22mm



DOG111  
Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



SH1  
Parallel axis helical gear, Machined plastic (delrin)



PDD  
Actuating plunger, Non-rotating detector shaft



G0  
Steel spur gear, Steel 20NCD2



BCM\_T  
Driving collar, Driving collar



CHM150  
Worm and wheel gear reducer, up to 107 Nm - Integrated



MDR\_SS  
Stainless steel Dee shackle with eye bolt, Stainless steel

## Complementary products



SBS\_M  
Single chain supplied by the metre, Stainless steel



PCS37  
Chain sprocket - steel, 9.525mm (DIN06B-1)



TCXR  
Automatic chain tensioner, With stainless steel sprocket



PCS\_PA6  
Plastic sprocket, 9.525mm (DIN 06B-1)